


End plate VMPAL-EPR-SP

Part number: 560947

FESTO

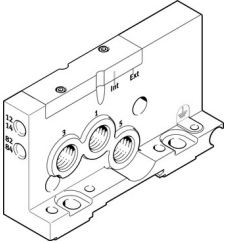

Data sheet

Feature	Value
Width	28.8 mm
Length	107.3 mm
Type code	VMPAL
Integrated function	Coding cover for determining the control air supply (internal or external)
Flow direction	Reversible
Valve manifold design	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	3 - High corrosion stress
Degree of protection	IP65 IP67
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	180 g
Pilot air port 12/14	M7
Pilot exhaust air port 82/84	M7
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum PA-reinforced