


# Power supply module VMPAL-SP-QS10

Part number: 560951

FESTO

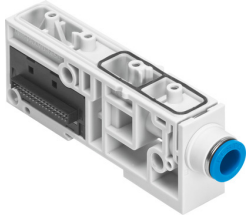

## Data sheet

Feature	Value
Width	23.2 mm
Length	107.3 mm
Type code	VMPAL
Integrated function	With electrical manifold module
Valve manifold design	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	3 - High corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	50 g
Pneumatic connection 1	for pneumatic tubing outside diameter 10 mm
Note on materials	RoHS-compliant
Power supply module material	Wrought aluminum alloy PA-reinforced