


# Electrical manifold module VMPAL-EVAP-14-1-4

Part number: 560969

FESTO

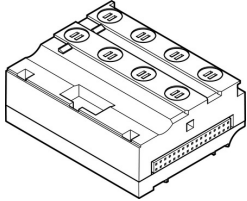

## Data sheet

Feature	Value
Valve size	14 mm
Type code	VMPAL
Max. no. of valve positions	4
Max. no. of solenoid coils	4
Integrated function	Valve function assignment color-coded
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	29 g
Housing colour	Gray
Housing material	PA
Note on materials	RoHS-compliant