


Connecting cable VMPAL-KMSK-S-SD25-IP67-

Part number: 562394

FESTO

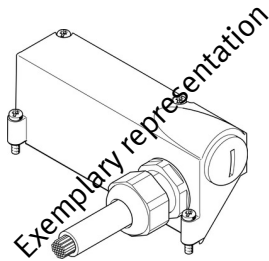

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Type code	VMPAL
Electrical connection	Cable with plug
Cable characteristic	Suitable for energy chains
Min. cable bending radius	63 mm
Cable diameter	12.5 mm
Cable design	25 x 0.34 mm ²
Degree of protection	IP67 as per IEC 60529
Ambient temperature with flexible cable installation	-5 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	TPE-U(PU)