
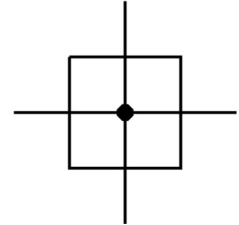


# Branching module MS9-FRM-NG-VS

Part number: 564148

FESTO

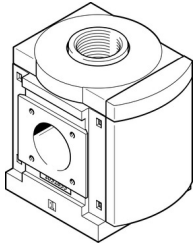

## Data sheet

Feature	Value
Size	9
Type code	MS9-FRM
Series	MS
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 20 bar
Operating voltage range AC	0 V ... 250 V
DC operating voltage range	0 V ... 125 V
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	1000 g
Type of mounting	Optionally: Front panel mounting Line installation With accessories
Pneumatic connection 3	1 NPT
Pneumatic connection 4	1 NPT
Covering material	PA-reinforced
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum
Material of mounting bracket	Die-cast aluminum
Housing material	Die-cast aluminum
Module connector material	Die-cast aluminum