


# Manifold rail VABM-L1-10AW-M7-4

Part number: 566548

FESTO

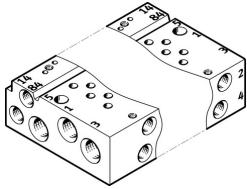

## Data sheet

| Feature                                     | Value  |
|---|--|
| Width dimension                             | 10.5 mm  |
| Type code                                   | VABM   |
| Max. no. of valve positions                 | 16   |
| Operating pressure                          | -0.09 MPa ... 1 MPa                              |
| Operating pressure                          | -0.9 bar ... 10 bar                              |
| Certification                               | RCM compliance mark<br>c UL us - Recognized (OL) |
| Corrosion resistance class (CRC)            | 2 - Moderate corrosion stress                    |
| Max. tightening torque for H-rail mounting: | 1.5 Nm   |
| Max. tightening torque for valve mounting   | 0.45 Nm  |
| Max. tightening torque for wall mounting    | 1.5 Nm   |
| Product weight                              | 96 g   |
| Pilot air port 12/14                        | M5   |
| Pilot exhaust air port 82/84                | M5   |
| Pneumatic connection 1                      | M7   |
| Pneumatic connection 2                      | M5   |
| Pneumatic connection 3                      | M7   |
| Pneumatic connection 4                      | M5   |
| Pneumatic connection 5                      | M7   |
| Note on materials                           | RoHS-compliant                                   |
| Manifold rail material                      | Wrought aluminum alloy                           |