
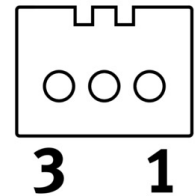


# Plug socket with cable NEBV-H1G2-KN-0.5-N-LE2

Part number: 566654

FESTO

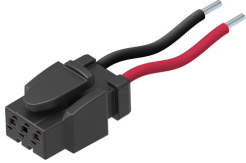

## Data sheet

Feature	Value
Type code	NEBV
Cable designation	Without label holder
Mounting position	Any
Product weight	4 g
Electrical connection 1, function	Field device end
Electrical connection 1, design	Rectangular
Electrical connection 1, connection type	Socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	Connection diagram H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-locking
Electrical connection for input 1, connection pattern	00995622
Electrical connection 2, function	Control side
Electrical connection 2, connection type	2x single wires
Electrical connection 2, connection technology	Open end
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
DC operating voltage range	0 V ... 60 V
Current rating at 40°C	3 A
Cable length	0.5 m
Cable characteristic	Standard
Cable diameter	1.3 mm
Cable design	2 x 0.14 mm <sup>2</sup>
Nominal conductor cross section	0.14 mm <sup>2</sup>
Wire ends	Cut off bluntly
Degree of protection	IP40
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 60 °C
Note on materials	RoHS-compliant
Housing material	POM
Housing colour	Black

Feature	Value
Material of pin contacts	Copper alloy Tin-plated
Insulating sheath material	PVC