


Push-in connector QBM-1/4T-5/32-U

Part number: 573058

FESTO

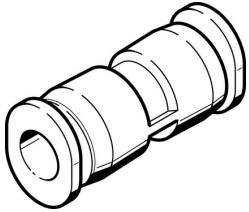

Data sheet

Feature	Value
Size	Mini
Nominal width	3.505 mm
Type code	QBM
Mounting position	Any
Structural design	Push-pull principle
Operating pressure for entire temperature range	-0.951 bar ... 9.997 bar
Temperature-dependent operating pressure	-0.951 bar ... 9.997 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	0 °C ... 60 °C
Product weight	3.005 g
Pneumatic connection 1	For pneumatic tubing outside diameter 1/4"
Pneumatic connection 2	for pneumatic tubing outside diameter 5/32"
Releasing ring color	Gray
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Housing material	PBT
Releasing ring material	POM
Material of tubing seal	NBR
Material of tube retaining claw	High-alloy stainless steel