


# Vertical pressure exhaust plate VABF-L1-P7A13-M7

FESTO

Part number: 574594

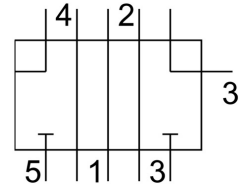

## Data sheet

Feature	Value
Width dimension	10.5 mm
Type code	VABF
Max. no. of valve positions	1
Symbol	00995307
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Certification	RCM compliance mark c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Max. tightening torque for valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection 3	M7
Pneumatic connection 5	M7
Note on materials	RoHS-compliant
Plate material	Wrought aluminum alloy