


# Supply plate VABF-B10-20-P1-G18

Part number: 576491

FESTO

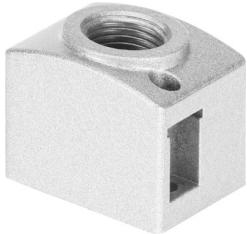

## Data sheet

Feature	Value
Type code	VABF
Operating pressure	-0.9 bar ... 10 bar
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Max. tightening torque	1.4 Nm
Product weight	13 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/8
Note on materials	RoHS-compliant
Supply plate material	Die-cast aluminum