


Stem actuated valve V-3-1/4-B

Part number: 6808

FESTO

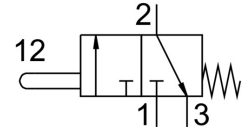

Data sheet

| Feature | Value |
|-------------------------------------|--|
| Valve function | 3/2, closed, monostable |
| Actuation type | Mechanical |
| Standard nominal flow rate | 600 l/min |
| Pneumatic working port | G1/4 |
| Operating pressure | -0.95 bar ... 10 bar |
| Structural design | Plate seat |
| Nominal width | 7 mm |
| Type code | V |
| Type of control | Direct |
| Symbol | 00991095 |
| Explosion prevention and protection | Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX) |
| Ambient temperature | -10 °C ... 60 °C |
| Actuating force | 70 N |
| Product weight | 130 g |
| Type of mounting | With through-hole |
| Pneumatic connection 1 | G1/4 |
| Pneumatic connection 2 | G1/4 |
| Pneumatic connection 3 | G1/4 |
| Seals material | NBR |
| Housing material | Die-cast aluminum |