


PE converter PE-VK-5.1

Part number: 7451

FESTO

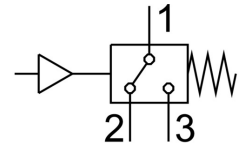

Data sheet

Feature	Value
Type code	PE
Symbol	00991470
Certification	CCC
CE marking (see declaration of conformity)	As per EU low voltage directive
Measured variable	Relative pressure
Method of measurement	Pneumatic/electric pressure transducer
Operating pressure	0 MPa ... 0.025 MPa
Operating pressure	0 bar ... 0.25 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Information on operating and pilot media	Operation with oil lubrication not possible
Temperature of medium	-10 °C ... 50 °C
Ambient temperature	-10 °C ... 50 °C
Switching element function	Changeover switch
Switch-on point	5.0E-4 bar
Switch-off point	1.0E-4 bar
Max. switching output voltage AC	250 V
Max. switching output voltage DC	250 V
Electrical connection	4-wire Cable
Type of mounting	Optionally: On mounting frame 1n With through-hole
Mounting position	Any
Pneumatic connection	M5
Product weight	250 g
Degree of protection	IP62