


Supply plate VABF-B10-25-P1A4-G14

Part number: 8026318

FESTO

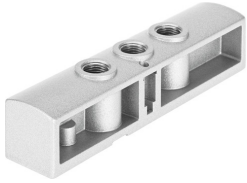

Data sheet

Feature	Value
Type code	VABF
Operating pressure	-0.9 bar ... 10 bar
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Max. tightening torque	3 Nm
Product weight	110 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Supply plate material	Die-cast aluminum