


# End plate VABE-S1-2RZ-N34

Part number: 8032673

FESTO

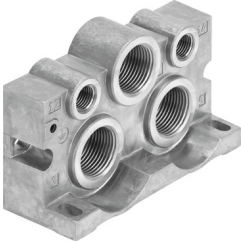

## Data sheet

Feature	Value
Width	44 mm
Type code	VABE
Exhaust air function	Via throttle plate
Based on norm	ISO 5599-1
Operating pressure	0 bar ... 10 bar
Suitability for vacuum	yes
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Storage temperature	-20 °C ... 60 °C
Temperature of medium	-10 °C ... 50 °C
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-10 °C ... 50 °C
Product weight	370 g
Type of mounting	with through-hole for M6 screw
Pilot air port 12/14	1/4 NPT
Pneumatic connection 1	3/4 NPT
Pneumatic connection 3	3/4 NPT
Pneumatic connection 5	3/4 NPT
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum