


Roller lever VAOM-R4-20-D1-32

Part number: 8049235

FESTO

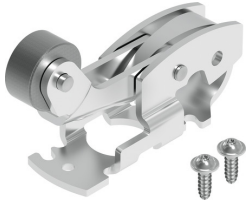

Data sheet

Feature	Value
Width	20 mm
Type code	VAOM
Actuation type	Mechanical
Mounting position	Movement plane
Structural design	Roller lever
Type of control	Direct
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Type of mounting	Screwed tightly
Note on materials	RoHS-compliant
Actuator attachments material	Steel, galvanized