


Mounting plate VABS-B14-90-FF14

Part number: 8098888

FESTO

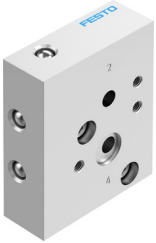

Data sheet

| Feature | Value |
|----------------------------------|--|
| Type code | VABS |
| Mounting position | Any |
| Structural design | Connections rotated 90° |
| Operating pressure | 1.5 bar ... 10 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7::-] |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Storage temperature | -20 °C ... 60 °C |
| Temperature of medium | -20 °C ... 60 °C |
| Ambient temperature | -20 °C ... 60 °C |
| Product weight | 255.5 g |
| Type of mounting | With through-hole |
| Pneumatic connection 2 | Flange 1/4 with NAMUR port pattern |
| Pneumatic connection 4 | Flange 1/4 with NAMUR port pattern |
| Note on materials | Contains paint-wetting impairment substances RoHS-compliant |
| Material of sub-base | Wrought aluminum alloy |