


# Mounting plate VABS-B14-270-FF14

Part number: 8098891

FESTO

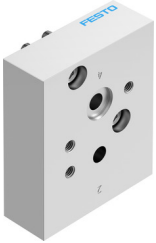

## Data sheet

Feature	Value
Type code	VABS
Mounting position	Any
Structural design	Connections rotated 270°
Operating pressure	1.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-20 °C ... 60 °C
Temperature of medium	-20 °C ... 60 °C
Ambient temperature	-20 °C ... 60 °C
Product weight	255.5 g
Type of mounting	With through-hole
Pneumatic connection 2	Flange 1/4 with NAMUR port pattern
Pneumatic connection 4	Flange 1/4 with NAMUR port pattern
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Material of sub-base	Wrought aluminum alloy