


Terminal strip NECC-L8G5-C1

Part number: 8106756

FESTO

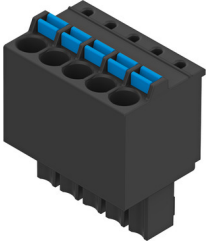

Data sheet

| Feature | Value |
|---|--|
| Type code | NECC |
| Cable outlet | Straight |
| Product weight | 3.8 g |
| Pack size | 1 |
| Electrical connection 1, design | Rectangular |
| Electrical connection 1, connection type | Socket |
| Electrical connection 1, connection technology | Connection diagram L8 |
| Electrical connection 1, number of pins/wires | 5 |
| Electrical connection 1, type of mounting | Inserted |
| Electrical connection for input 1, connection pattern | 00997297 |
| Electrical connection 2, connection technology | Spring-loaded terminal |
| DC operating voltage range | 0 V ... 300 V |
| Current rating at 40°C | 8 A |
| Surge resistance | 1.6 kV |
| Shield | no |
| Nominal conductor cross section | AWG28 - 16 |
| Degree of protection | IP20 |
| Note on degree of protection | In mounted state |
| Ambient temperature | -40 °C ... 115 °C |
| Note on materials | Contains paint-wetting impairment substances RoHS-compliant |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| Housing material | PA |
| Housing colour | Black |