


Pilot valve

VOFX-LT-M32C-MY-G18-SG18-1B2

Part number: 8119587

FESTO

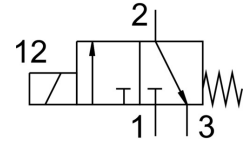

Data sheet

Feature	Value
Valve function	3/2, closed, monostable
Actuation type	Electrical
Width	22 mm
Standard nominal flow rate	50 l/min
Pneumatic working port	G1/8
Operating voltage	24V DC
Operating pressure	-0.9 bar ... 8 bar
Structural design	Directly controlled poppet valve
Reset method	Mechanical spring
Degree of protection	IP65
Nominal width	1,3 mm
Type code	VOFX
Exhaust air function	With flow control option
Sealing principle	Soft
Mounting position	Any
Manual override	Detenting
Type of control	Direct
Pilot air supply port	Internal
Flow direction	Non-reversible
Symbol	00991135
Switching time off	46 ms
On switching time	31 ms
Duty cycle	100%
Coil characteristics	24 V DC: 3.0 W
Permissible voltage fluctuations	+/- 10 %
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Temperature of medium	-10 °C ... 50 °C
Ambient temperature	-10 °C ... 50 °C
Product weight	160 g
Electrical connection	3-pin Form B Plug as per EN 175301-803
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8

Feature	Value
Pneumatic connection 3	M5
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Seals material	NBR
Housing material	PA