


Distributor block FR-12-PK-3-B

Part number: 8761

FESTO

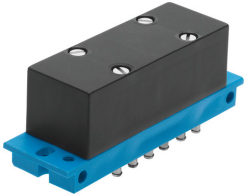

Data sheet

Feature	Value
Nominal width	2.5 mm
Type code	FR
Mounting position	Any
Operating pressure for entire temperature range	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
No. of outlets	12
No. of supply lines	1
Pneumatic connection 1	Internal thread G1/4
Pneumatic connection 2	for pneumatic tubing outside diameter 4 mm
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum