



R-259

Heavy-duty impact gloves with a Kevlar®-stitched palm for advanced cut resistance



Impact

Abrasion Protection



Cut



Heavy Duty

Heavy-duty impact gloves with an additional palm layer, for advanced cut resistance

- **Heightened defenses:** RINGERS® R259 heavy-duty work gloves are developed with a TPR (thermoplastic rubber) design and F3 Technology™ to deliver impact protection with dexterity and comfort
- **Improved grip and durability:** Their synthetic leather palm offers wearers better grip, while ensuring advanced EN- and ANSI-compliant abrasion resistance
- **Added protection:** These impact gloves' Kevlar®-stitched additional palm layer grants EN 388 level E and ANSI/ISEA level A5 cut resistance, for truly dependable hand protection
- **Enhanced features:** These RINGERS® gloves also feature an extended neoprene wrist closure, ensuring a secure fit, while a high-visibility external surface improves worker safety



Industries

- Manufacturing
- Oil and gas

Applications

- Engagement and release of drill string slips
- Chaining up pipes
- Installation and dismantling of rigs
- Environmental clean-up and remediation
- Handling iron
- Maintenance
- Operating of heavy machinery
- Equipment maintenance and repair
- Pipe handling
- Loading and hauling



R-259


Heavy-duty impact gloves with a Kevlar®-stitched palm for advanced cut resistance

Key Features

- **Patented TPR design:** Finger-length and top-of-hand impact protection
- **Synthetic leather palm:** For increased durability and grip
- **Additional palm layer:** Advanced cut resistance

Performance Standards & Regulatory Compliance

REACH Compliant

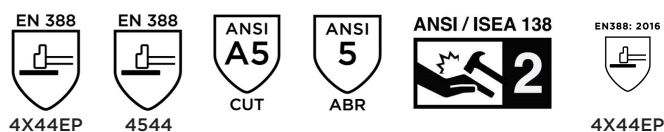

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	COLOR	PACKAGE
RINGERS® R259	Liner Material: HPPE Cuff Style: Extended neoprene wrist closure		7, 8, 9, 10, 11, 12, 13	Hi Viz	5 pairs/bag, 10 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jaijan Teknokrat 6
T: +603 8310 6888
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2022 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

