



**CES 2020**  
Smart Home



**CES 2020**  
Smart City

# Athena

## Biometric Outdoor Security Camera



### SPECIFICATION


Model (Athena)	ACR2002G1	Resolution	2M Pixels FHD
Encryption Technology	256-bit	Streaming Quality	Automatically Adjusted
Privacy Protection	Yes	Video Compression	H.264
Wireless	Embedded Wi-Fi (2.4GHz) 802.11 b/g/n	Video Resolution	1080p, 720p, 480p, 360p
Multiple Wi-Fi Routers Support	Up to 4 Wi-Fi routers	Image Distortion	<12%
Snapshot / Text / Offline Alert	Yes	Image Sensor	1/2.7" CMOS
Audio	Built-in Speaker and Microphone	IR	IR LEDs: 12
Real-Time Two-Way Communication	Yes	MIMO Antenna	Embedded 2 x 2
10-Second Video Alert	Yes <sup>1</sup>	Local Storage	Supports up to 128GB MicroSD Card
Greetings Function	Yes	App Support	Amaryllo
Motion / Audio Detection	Yes	Mobile OS Requirements	iOS 10.0 and up / Android 5.0 and up
Fire Warning	Yes <sup>1</sup>	Google Services Connection	Yes
Face Detection	Yes <sup>1</sup>	PC Browser Support	Chrome / Firefox
Human Detection	Edge AI	Network Protocol	TCP/IP, UDP/IP, HTTP/HTTPS, DHCP, NTP, WPS
Pet / Vehicle Detection	Yes <sup>1</sup>	NAS Support	SMB / CIFS
Day / Night Vision	Yes	Power Consumption	100V ~ 240V (12V/1A DC)
Intruder Warning Alarm	Yes	Dimensions (H x W x D)	8.1 x 8.1 x 23.2 / 3.2" x 3.2" x 9.2"
Multiple Viewers Support	Max: 4	Weight	590g / 1.3lb
Activity / Blockout Zones	93° (Diagonal)	Ingress Protection Rating	IP66
Field of View (FOV)	4x	Ambient Operating Temperature	-40°F ~ 140°F / -40°C ~ 60°C
Digital Zoom	Tilt: 0° ~ 90°	Warranty	One-Year Part Warranty
Tilt	1920 x 1080 up to 30 fps		
Frame Rate			

<sup>1</sup> Feature available under selected Amaryllo Protect Plans.

<sup>2</sup> Feature available under 24/7 Professional Monitoring Service.

# Athena

## ACCESSORIES

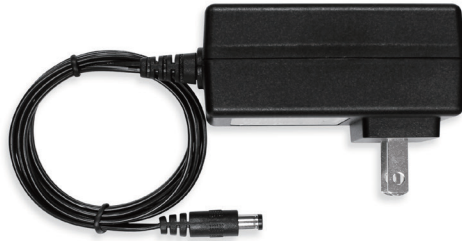

Power adapter

Screw anchor



Screw

