

Petite

Intelligent Pet Camera



Facial
recognition



Infrared Night
Vision



Heat Mapping



Military Encryption
Protection



Quick setup



10-Second
Video Alert



SPECIFICATION

Model (Petite)	ACC1308F1BL/ACC1308F1RD
Encryptions Technologies	256-bit
Privacy Protection	Yes
Wireless	Wi-Fi 2.4 GHz 802.11 /b/g/n
Multiple Wi-Fi Routers Support	Up to 4 Wi-Fi routers
1 Min Quick Setup	Yes
Snapshot / Text / Offline Alert	Yes
Audio	Built-in Speaker and Microphone
Real-Time Two-Way Communication	Yes
Smart AI Features	Yes
Greetings Function	Yes
Face /Motion / Audio Detection	Yes
Human Detection	Yes
Vehicle Detection	Yes
Day / Night Vision	Yes
Intruder Warning Light Alarm	No
Multiple Viewers Support	Yes
Auto Tracking Range	No
Activity / Blockout Zones	Max: 4
Field of View (FOV)	85±5° (Diagonal)
Digital Zoom	4x
Fixed Lens	1/3.2" (OV5653)


Pan / Tilt	Pan: -140° to 140° / Tilt: -25° to 25°
Frame Rate	1280 x 720 up to 30 fps
Resolution	1M Pixels HD
Streaming Quality	Automatically Adjusted
Video Compression	H.264, MJPEG
Video Resolution	720p, 480p, 360p
Image Sensor	1/4" CMOS
IR LEDs	8
Light Lamp	No
MIMO Antenna	Embedded 2x2
Local Storage	Supports up to 128GB Micro SD Card
App Support	Amaryllo
Mobile OS Requirements	iOS: 9.0 and up / Android: 4.1 and up
Google Services Connection	Yes
PC Browser Support	Chrome / Firefox
Network Protocol	TCP/IP, UDP/IP, HTTP/HTTPS, DHCP, NTP,WPS
NAS Support	SMB / CIFS
Power Consumption	100V ~ 240V (5V / 2A DC)
Dimensions (H x W x D)	8 x 8 x 8 cm / 3.15"x 3.15"x 3.15"
Weight	222g / 7.84 oz
Ambient Operating Temperature	32°F ~ 95°F / 0°C ~ 35°C
Warranty	One-Year Part Warranty

Petite

ACCESSORIES



Power adapter

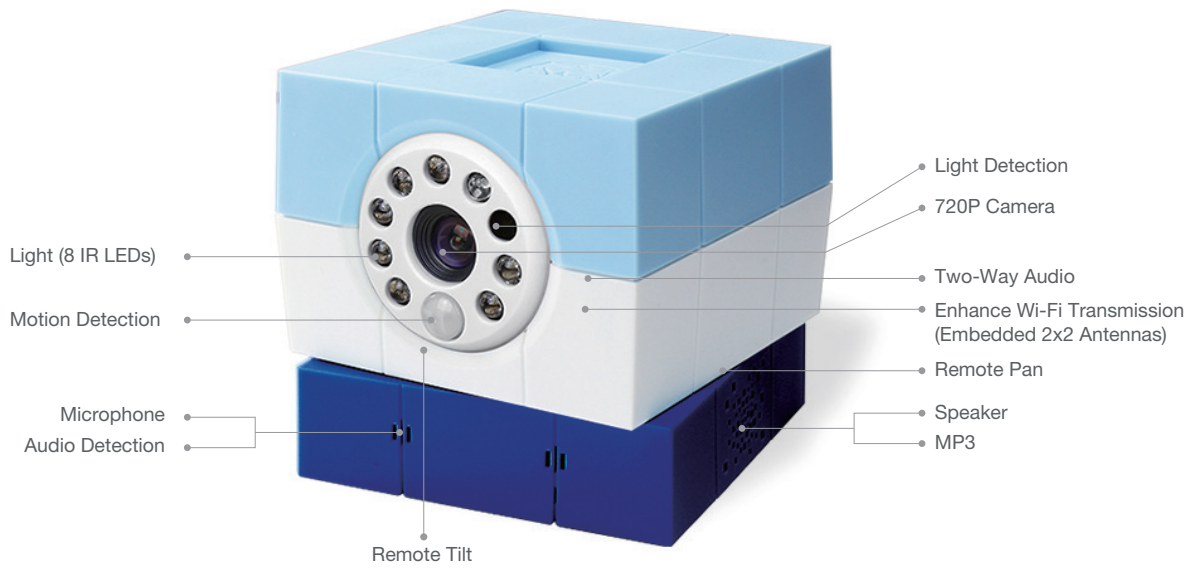

3.14"
8 cm

