


XL TIMING PULLEY FLANGES

0.200" / 5.08 mm Pitch
Steel

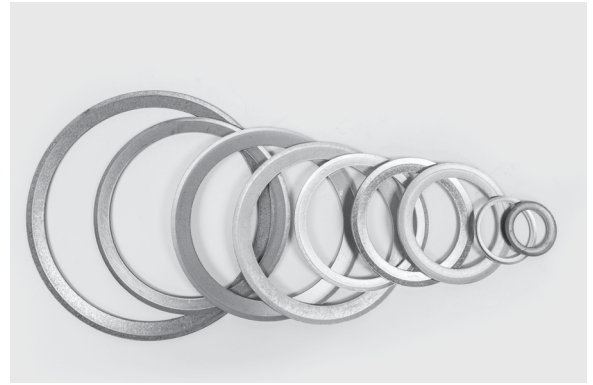

Part Number	Metric				Inch			
	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness
10XL-FS	12.8 mm	22.2 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.503"	0.875"	0.035/0.045"	0.060/0.070"
11XL-FS	14.3 mm	23.8 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.562"	0.938"	0.035/0.045"	0.060/0.070"
12XL-FS	14.3 mm	25.4 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.562"	1.000"	0.035/0.045"	0.060/0.070"
13XL-FS	15.9 mm	27.0 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.625"	1.063"	0.035/0.045"	0.060/0.070"
14XL-FS	17.4 mm	27.8 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.684"	1.094"	0.035/0.045"	0.060/0.070"
15XL-FS	19.0 mm	30.2 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.748"	1.188"	0.035/0.045"	0.060/0.070"
16XL-FS	20.6 mm	31.8 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.810"	1.250"	0.035/0.045"	0.060/0.070"
17XL-FS	22.5 mm	33.4 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.887"	1.313"	0.035/0.045"	0.060/0.070"
18XL-FS	23.8 mm	34.9 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	0.936"	1.375"	0.035/0.045"	0.060/0.070"
19XL-FS	25.4 mm	36.5 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.000"	1.438"	0.035/0.045"	0.060/0.070"
20XL-FS	27.0 mm	38.1 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.062"	1.500"	0.035/0.045"	0.060/0.070"
21XL-FS	28.6 mm	39.7 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.125"	1.563"	0.035/0.045"	0.060/0.070"
22XL-FS	29.5 mm	41.3 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.160"	1.625"	0.035/0.045"	0.060/0.070"
23XL-FS	31.0 mm	42.9 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.222"	1.688"	0.035/0.045"	0.060/0.070"
24XL-FS	31.0 mm	44.5 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.222"	1.750"	0.035/0.045"	0.060/0.070"
25XL-FS	31.8 mm	46.1 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.250"	1.813"	0.035/0.045"	0.060/0.070"
26XL-FS	34.2 mm	47.6 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.347"	1.875"	0.035/0.045"	0.060/0.070"
28XL-FS	36.2 mm	50.8 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.425"	2.000"	0.035/0.045"	0.060/0.070"
30XL-FS	39.4 mm	54.0 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.550"	2.125"	0.035/0.045"	0.060/0.070"
32XL-FS	42.5 mm	57.2 mm	0.9 mm/1.1 mm	1.5 mm/1.8 mm	1.675"	2.250"	0.035/0.045"	0.060/0.070"

Timing Pulley Flanges

