


# 2 MM POWERHOUSE™ TIMING PULLEY BAR STOCK

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)

## 2 mm Pitch Aluminum

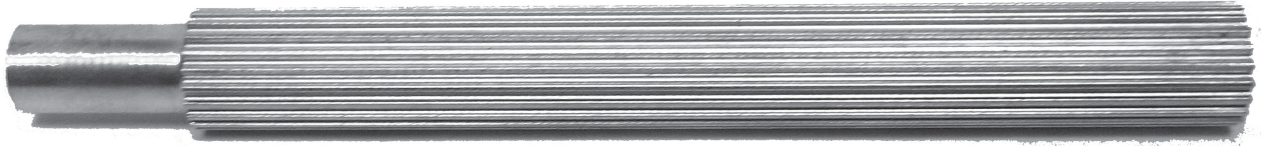

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
10-2P-PS2A	10	6.4 mm	5.9 mm	0.251"	0.231"	0.313"	1.000"	2.000"	3.000"
11-2P-PS2A	11	7.0 mm	6.5 mm	0.276"	0.256"	0.313"	1.000"	2.000"	3.000"
12-2P-PS2A	12	7.6 mm	7.1 mm	0.301"	0.281"	0.313"	1.000"	2.000"	3.000"
13-2P-PS2A	13	8.3 mm	7.8 mm	0.326"	0.306"	0.375"	1.000"	2.000"	3.000"
14-2P-PS3A	14	8.9 mm	8.4 mm	0.351"	0.331"	0.375"	1.000"	3.000"	4.000"
15-2P-PS3A	15	9.6 mm	9.0 mm	0.376"	0.356"	0.438"	1.000"	3.000"	4.000"
16-2P-PS3A	16	10.2 mm	9.7 mm	0.401"	0.381"	0.438"	1.000"	3.000"	4.000"
17-2P-PS3A	17	10.8 mm	10.3 mm	0.426"	0.406"	0.438"	1.000"	3.000"	4.000"
18-2P-PS3A	18	11.5 mm	10.9 mm	0.451"	0.431"	0.500"	1.000"	3.000"	4.000"
19-2P-PS3A	19	12.1 mm	11.6 mm	0.476"	0.456"	0.500"	1.000"	3.000"	4.000"
20-2P-PS4A	20	12.7 mm	12.2 mm	0.501"	0.481"	0.375"	0.875"	4.000"	4.875"
21-2P-PS4A	21	13.4 mm	12.9 mm	0.526"	0.506"	0.375"	0.875"	4.000"	4.875"
22-2P-PS4A	22	14.0 mm	13.5 mm	0.551"	0.531"	0.375"	0.875"	4.000"	4.875"
23-2P-PS4A	23	14.6 mm	14.1 mm	0.576"	0.556"	0.375"	0.875"	4.000"	4.875"
24-2P-PS5A	24	15.3 mm	14.8 mm	0.602"	0.582"	0.500"	1.000"	5.000"	6.000"
25-2P-PS5A	25	15.9 mm	15.4 mm	0.627"	0.607"	0.500"	1.000"	5.000"	6.000"
26-2P-PS5A	26	16.6 mm	16.1 mm	0.652"	0.632"	0.500"	1.000"	5.000"	6.000"
27-2P-PS5A	27	17.2 mm	16.7 mm	0.677"	0.657"	0.500"	1.000"	5.000"	6.000"
28-2P-PS5A	28	17.8 mm	17.3 mm	0.702"	0.682"	0.500"	1.000"	5.000"	6.000"
29-2P-PS5A	29	18.5 mm	18.0 mm	0.727"	0.707"	0.500"	1.000"	5.000"	6.000"
30-2P-PS6A	30	19.1 mm	18.6 mm	0.752"	0.732"	0.500"	1.000"	6.000"	7.000"
31-2P-PS6A	31	19.7 mm	19.2 mm	0.777"	0.757"	0.500"	1.000"	6.000"	7.000"
32-2P-PS6A	32	20.4 mm	19.9 mm	0.802"	0.782"	0.500"	1.000"	6.000"	7.000"
33-2P-PS6A	33	21.0 mm	20.5 mm	0.827"	0.807"	0.500"	1.000"	6.000"	7.000"
34-2P-PS6A	34	21.6 mm	21.1 mm	0.852"	0.832"	0.500"	1.000"	6.000"	7.000"