


MXL TIMING PULLEY BAR STOCK

0.080" / 2.03 mm Pitch
Aluminum

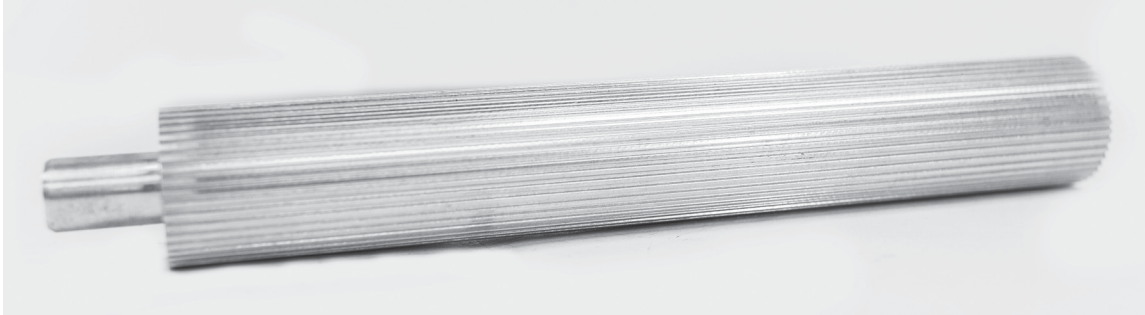

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
10MP-PS2A	10	6.5 mm	6.0 mm	0.255"	0.235"	0.188" - 0.219"	1.000"	2.000"	3.000"
11MP-PS2A	11	7.1 mm	6.6 mm	0.280"	0.260"	0.188" - 0.219"	1.000"	2.000"	3.000"
12MP-PS2A	12	7.8 mm	7.3 mm	0.306"	0.286"	0.188" - 0.219"	1.000"	2.000"	3.000"
13MP-PS2A	13	8.4 mm	7.9 mm	0.331"	0.311"	0.250"	1.000"	2.000"	3.000"
14MP-PS3A	14	9.1 mm	8.6 mm	0.357"	0.337"	0.250"	1.000"	3.000"	4.000"
15MP-PS3A	15	9.7 mm	9.2 mm	0.382"	0.362"	0.313"	1.000"	3.000"	4.000"
16MP-PS3A	16	10.3 mm	9.8 mm	0.407"	0.387"	0.313"	1.000"	3.000"	4.000"
17MP-PS3A	17	11.0 mm	10.5 mm	0.433"	0.413"	0.313"	1.000"	3.000"	4.000"
18MP-PS3A	18	11.6 mm	11.1 mm	0.458"	0.438"	0.375"	1.000"	3.000"	4.000"
19MP-PS3A	19	12.3 mm	11.8 mm	0.484"	0.464"	0.375"	1.000"	3.000"	4.000"
20MP-PS4A	20	12.9 mm	12.4 mm	0.509"	0.489"	0.375"	0.875"	4.000"	4.875"
21MP-PS4A	21	13.6 mm	13.1 mm	0.535"	0.515"	0.375"	0.875"	4.000"	4.875"
22MP-PS4A	22	14.2 mm	13.7 mm	0.560"	0.540"	0.375"	0.875"	4.000"	4.875"
23MP-PS4A	23	14.9 mm	14.4 mm	0.586"	0.566"	0.375"	0.875"	4.000"	4.875"
24MP-PS5A	24	15.5 mm	15.0 mm	0.611"	0.591"	0.500"	0.750"	5.000"	5.750"
25MP-PS5A	25	16.2 mm	15.7 mm	0.637"	0.617"	0.500"	0.750"	5.000"	5.750"
26MP-PS5A	26	16.8 mm	16.3 mm	0.662"	0.642"	0.500"	0.750"	5.000"	5.750"
27MP-PS5A	27	17.4 mm	16.9 mm	0.687"	0.667"	0.500"	0.750"	5.000"	5.750"
28MP-PS5A	28	18.1 mm	17.6 mm	0.713"	0.693"	0.500"	0.750"	5.000"	5.750"
29MP-PS5A	29	18.7 mm	18.2 mm	0.738"	0.718"	0.500"	0.750"	5.000"	5.750"
30MP-PS6A	30	19.4 mm	18.9 mm	0.764"	0.744"	0.500"	0.750"	6.000"	6.750"
31MP-PS6A	31	20.0 mm	19.4 mm	0.789"	0.763"	0.500"	0.750"	6.000"	6.750"
32MP-PS6A	32	20.7 mm	20.2 mm	0.815"	0.795"	0.500"	0.750"	6.000"	6.750"
33MP-PS6A	33	21.3 mm	20.8 mm	0.840"	0.820"	0.500"	0.750"	6.000"	6.750"
34MP-PS6A	34	22.0 mm	21.5 mm	0.866"	0.846"	0.500"	0.750"	6.000"	6.750"