


5 MM POWERHOUSE™ HTD® TIMING PULLEY FLANGES

5 mm Pitch
Steel

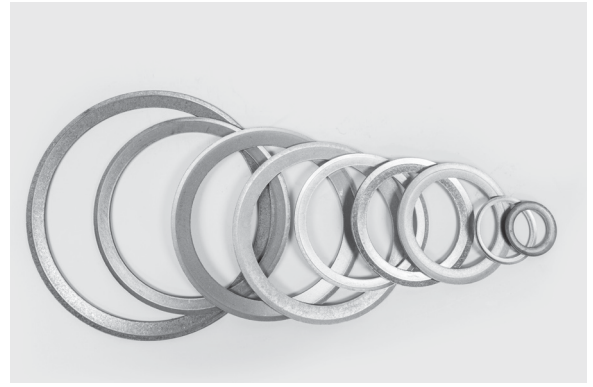

Part Number	Metric				Inch			
	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness
12-5M-FS	12.8 mm	22.2 mm	1.0 mm	1.7 mm	0.503"	0.875"	0.040"	0.065"
13-5M-FS	14.3 mm	23.8 mm	1.0 mm	1.7 mm	0.562"	0.937"	0.040"	0.065"
14-5M-FS	14.3 mm	25.4 mm	1.0 mm	1.7 mm	0.562"	1.000"	0.040"	0.065"
15-5M-FS	15.9 mm	27.0 mm	1.0 mm	1.7 mm	0.625"	1.062"	0.040"	0.065"
16-5M-FS	17.4 mm	27.8 mm	1.0 mm	1.7 mm	0.684"	1.093"	0.040"	0.065"
17-5M-FS	19.0 mm	30.1 mm	1.0 mm	1.7 mm	0.748"	1.187"	0.040"	0.065"
18-5M-FS	20.6 mm	31.8 mm	1.0 mm	1.7 mm	0.810"	1.250"	0.040"	0.065"
19-5M-FS	22.5 mm	33.3 mm	1.0 mm	1.7 mm	0.887"	1.312"	0.040"	0.065"
20-5M-FS	23.8 mm	34.9 mm	1.0 mm	1.7 mm	0.936"	1.375"	0.040"	0.065"
21-5M-FS	25.4 mm	36.5 mm	1.0 mm	1.7 mm	1.000"	1.437"	0.040"	0.065"
22-5M-FS	27.0 mm	38.1 mm	1.0 mm	1.7 mm	1.062"	1.500"	0.040"	0.065"
23-5M-FS	28.6 mm	39.7 mm	1.0 mm	1.7 mm	1.125"	1.562"	0.040"	0.065"
24-5M-FS	29.5 mm	41.3 mm	1.0 mm	1.7 mm	1.160"	1.625"	0.040"	0.065"
25-5M-FS	31.0 mm	42.8 mm	1.0 mm	1.7 mm	1.222"	1.687"	0.040"	0.065"
26-5M-FS	31.0 mm	44.5 mm	1.0 mm	1.7 mm	1.222"	1.750"	0.040"	0.065"
28-5M-FS	34.2 mm	47.6 mm	1.0 mm	1.7 mm	1.347"	1.875"	0.040"	0.065"
30-5M-FS	36.2 mm	50.8 mm	1.0 mm	1.7 mm	1.425"	2.000"	0.040"	0.065"
32-5M-FS	39.4 mm	54.0 mm	1.0 mm	1.7 mm	1.550"	2.125"	0.040"	0.065"
34-5M-FS	42.5 mm	57.2 mm	1.0 mm	1.7 mm	1.675"	2.250"	0.040"	0.065"

Timing Pulley Flanges



At B&B Manufacturing, we have an extensive online catalog of off-the-shelf parts that meet a wide variety of needs in the power transmission and precision mechanical marketplaces.

But we know that sometimes it takes something special to do the job right. That's why we can modify any of our stock components to meet your unique performance and material specifications. We also offer fast, precision-engineered and quality manufactured components that can be built from the ground up in our custom shop.