



POWERHOUSE MX™ TIMING PULLEYS

(Compatible with Poly Chain® GT® Carbon belts)

5 mm Pitch
For 25 mm Wide Belts
Flanges
Steel/Iron
Black Oxide Plating



Part Number	No. of Teeth	Type	Pitch Dia. (in)	Out. Dia. (in)	Flange Dia. (in)	Bore/Bushing	Face Width (in)	Overall Length (in)
18-5MX25-6FS3	18	6F	1.128	1.083	1.375	0.250	1.280	1.650
19-5MX25-6FS3	19	6F	1.191	1.146	1.438	0.250	1.280	1.650
20-5MX25-6FS3	20	6F	1.253	1.208	1.531	0.250	1.280	1.650
21-5MX25-6FS3	21	6F	1.316	1.271	1.531	0.250	1.280	1.650
22-5MX25-6FS3	22	6F	1.379	1.334	1.656	0.250	1.280	1.680
23-5MX25-6FS5	23	6F	1.441	1.396	1.656	0.375	1.280	1.680
24-5MX25-6FS5	24	6F	1.504	1.459	1.781	0.375	1.280	1.680
25-5MX25-6FS5	25	6F	1.566	1.521	1.781	0.375	1.280	1.680
26-5MX25-6FS5	26	6F	1.629	1.584	1.906	0.375	1.280	1.680
28-5MX25-6FS6	28	6F	1.754	1.709	2.031	0.375	1.280	1.730
30-5MX25-6FS6	30	6F	1.880	1.835	2.125	0.500	1.280	1.730
32-5MX25-6FS6	32	6F	2.005	1.960	2.125	0.500	1.280	1.730
34-5MX25-6FS6	34	6F	2.130	2.085	2.375	0.500	1.280	1.730
36-5MX25-6FS6	36	6F	2.256	2.211	2.375	0.500	1.280	1.730
38-5MX25-6FS6	38	6F	2.381	2.336	2.625	0.500	1.280	1.730
40-5MX25-6FS6	40	6F	2.506	2.461	2.750	0.500	1.280	1.780
45-5MX25-6FS6	45	6F	2.820	2.775	3.094	0.500	1.280	1.780
50-5MX25-6FS6	50	6F	3.133	3.088	3.330	0.500	1.280	1.780
36-5MX25-1108	36	A1F	2.256	2.211	2.375	1108	1.290	1.290
38-5MX25-1108	38	A1F	2.381	2.336	2.625	1108	1.290	1.290
40-5MX25-1108	40	A1F	2.506	2.461	2.750	1108	1.290	1.290
44-5MX25-1108	44	A1F	2.757	2.712	3.094	1108	1.290	1.290
48-5MX25-1210	48	A1F	3.008	2.963	3.330	1210	1.280	1.280
52-5MX25-1210	52	A1F	3.258	3.213	3.566	1210	1.280	1.280
56-5MX25-1610	56	A1F	3.509	3.464	3.800	1610	1.280	1.280
60-5MX25-1610	60	A1F	3.760	3.715	4.044	1610	1.280	1.280
64-5MX25-1610	64	A1F	4.010	3.965	4.170	1610	1.280	1.280
68-5MX25-2012	68	A1F	4.261	4.216	4.520	2012	1.280	1.280
72-5MX25-2012	72	A1F	4.511	4.466	4.670	2012	1.280	1.280

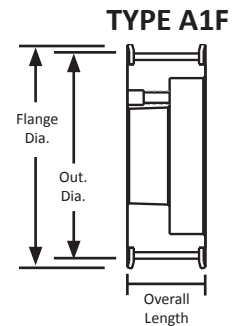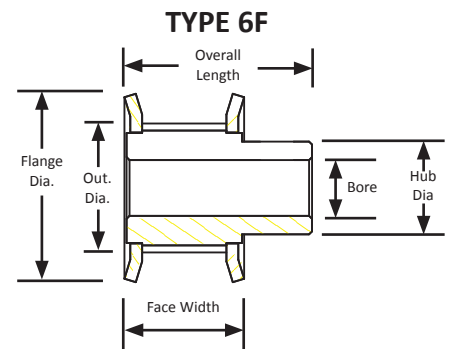

For idler pulleys,
see page 366.