

# A-B COMBINATION V-BELT SHEAVES

For use with "A" or "B" Section Belts

1 Groove

0.875" Face Width


Cast Iron

QD® Style




Part Number	Type	Pitch Dia. "A" belts (in)	Pitch Dia. "B" belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
1B34SH	E1	3.0	3.4	3.00	SH	0.500" - 1.625"	0.219	1.313	0.656	2.0
1B36SH	D1	3.2	3.6	3.95	SH	0.500" - 1.625"	0.594	1.313	0.156	2.2
1B38SH	D1	3.4	3.8	4.15	SH	0.500" - 1.625"	0.594	1.313	0.156	2.4
1B40SH	C1	3.6	4.0	4.35	SH	0.500" - 1.625"	0.344	1.313	0.094	2.7
1B42SH	C1	3.8	4.2	4.55	SH	0.500" - 1.625"	0.344	1.313	0.094	2.9
1B44SH	C1	4.0	4.4	4.75	SH	0.500" - 1.625"	0.344	1.313	0.094	3.4
1B46SDS	C1	4.2	4.6	4.95	SDS	0.500" - 2.000"	0.344	1.313	0.094	4.0
1B48SDS	C1	4.4	4.8	5.15	SDS	0.500" - 2.000"	0.344	1.313	0.094	4.3
1B50SDS	C1	4.6	5.0	5.35	SDS	0.500" - 2.000"	0.344	1.313	0.094	4.7
1B52SDS	C1	4.8	5.2	5.55	SDS	0.500" - 2.000"	0.344	1.313	0.094	5.0
1B54SDS	C1	5.0	5.4	5.75	SDS	0.500" - 2.000"	0.344	1.313	0.094	5.3
1B56SDS	C1	5.2	5.6	5.95	SDS	0.500" - 2.000"	0.344	1.313	0.094	5.6
1B58SDS	C2	5.4	5.8	6.15	SDS	0.500" - 2.000"	0.344	1.313	0.094	5.9
1B60SDS	C2	5.6	6.0	6.35	SDS	0.500" - 2.000"	0.344	1.313	0.094	6.2
1B62SDS	C2	5.8	6.2	6.55	SDS	0.500" - 2.000"	0.344	1.313	0.094	6.5
1B64SDS	C2	6.0	6.4	6.75	SDS	0.500" - 2.000"	0.344	1.313	0.094	6.8
1B66SDS	C2	6.2	6.6	6.95	SDS	0.500" - 2.000"	0.344	1.313	0.094	7.2
1B68SDS	C3	6.4	6.8	7.15	SDS	0.500" - 2.000"	0.344	1.313	0.094	7.5
1B70SDS	C3	6.6	7.0	7.35	SDS	0.500" - 2.000"	0.344	1.313	0.094	7.8
1B74SDS	D3	7.0	7.4	7.75	SDS	0.500" - 2.000"	0.531	1.313	0.219	8.8
1B80SDS	D3	7.6	8.0	8.35	SDS	0.500" - 2.000"	0.531	1.313	0.219	9.6
1B86SDS	D3	8.2	8.6	8.95	SDS	0.500" - 2.000"	0.531	1.313	0.219	10.0
1B94SDS	D3	9.0	9.4	9.75	SDS	0.500" - 2.000"	0.531	1.313	0.219	10.5
1B110SDS	D3	10.6	11.0	11.35	SDS	0.500" - 2.000"	0.531	1.313	0.219	11.0
1B124SDS	D3	12.0	12.4	12.75	SDS	0.500" - 2.000"	0.531	1.313	0.219	12.0
1B136SDS	D3	13.2	13.6	13.95	SDS	0.500" - 2.000"	0.531	1.313	0.219	14.0
1B154SK	C3	15.0	15.4	15.75	SK	0.500" - 2.625"	0.656	1.938	0.281	16.0
1B160SK	C3	15.6	16.0	16.35	SK	0.500" - 2.625"	0.656	1.938	0.281	16.6
1B184SK	C3	18.0	18.4	18.75	SK	0.500" - 2.625"	0.656	1.938	0.281	18.0
1B200SK	C3	19.6	20.0	20.35	SK	0.500" - 2.625"	0.656	1.938	0.281	20.0

**TYPE A**

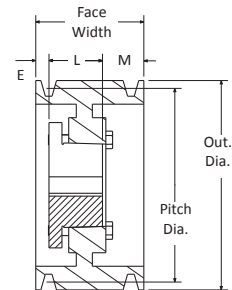

**TYPE D**

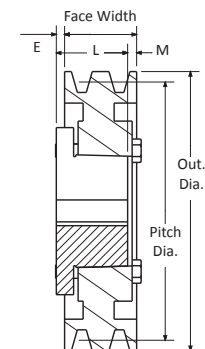

**TYPE E**

