


# 2 MM POWERHOUSE™ TIMING PULLEY FLANGES

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)

2 mm Pitch  
Aluminum

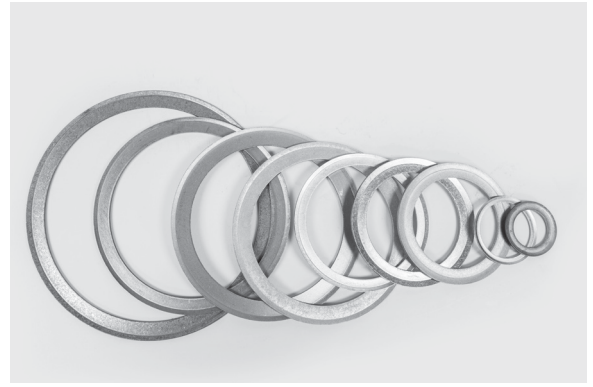

Part Number	Metric				Inch			
	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness	Inside Diameter	Outside Diameter	Stock Thickness	Overall Formed Thickness
10-2P-FA	4.8 mm	10.8 mm	0.6 mm	1.1 mm	0.188"	0.425"	0.025"	0.045"
11-2P-FA	5.4 mm	11.4 mm	0.6 mm	1.1 mm	0.214"	0.450"	0.025"	0.045"
12-2P-FA	5.5 mm	12.2 mm	0.6 mm	1.1 mm	0.218"	0.480"	0.025"	0.045"
13-2P-FA	6.2 mm	12.8 mm	0.6 mm	1.1 mm	0.244"	0.505"	0.025"	0.045"
14-2P-FA	6.9 mm	13.5 mm	0.6 mm	1.1 mm	0.270"	0.530"	0.025"	0.045"
15-2P-FA	7.5 mm	14.1 mm	0.6 mm	1.1 mm	0.296"	0.555"	0.025"	0.045"
16-2P-FA	8.2 mm	14.7 mm	0.6 mm	1.1 mm	0.322"	0.580"	0.025"	0.045"
18-2P-FA	9.5 mm	16.1 mm	0.8 mm	1.3 mm	0.374"	0.635"	0.032"	0.052"
20-2P-FA	10.8 mm	17.4 mm	0.8 mm	1.3 mm	0.426"	0.685"	0.032"	0.052"
21-2P-FA	10.8 mm	18.0 mm	0.8 mm	1.3 mm	0.426"	0.710"	0.032"	0.052"
22-2P-FA	11.5 mm	18.8 mm	0.8 mm	1.3 mm	0.452"	0.740"	0.032"	0.052"
24-2P-FA	12.8 mm	20.1 mm	0.8 mm	1.3 mm	0.504"	0.790"	0.032"	0.052"
25-2P-FA	13.5 mm	20.7 mm	0.8 mm	1.3 mm	0.530"	0.815"	0.032"	0.052"
26-2P-FA	14.1 mm	21.3 mm	0.8 mm	1.3 mm	0.556"	0.840"	0.032"	0.052"
28-2P-FA	14.6 mm	22.7 mm	0.8 mm	1.3 mm	0.574"	0.895"	0.032"	0.052"
30-2P-FA	15.9 mm	24.0 mm	0.8 mm	1.3 mm	0.626"	0.945"	0.032"	0.052"
32-2P-FA	17.2 mm	25.4 mm	0.8 mm	1.3 mm	0.678"	1.000"	0.032"	0.052"
33-2P-FA	17.9 mm	26.0 mm	0.8 mm	1.3 mm	0.704"	1.025"	0.032"	0.052"
34-2P-FA	18.3 mm	26.7 mm	0.8 mm	1.3 mm	0.722"	1.050"	0.032"	0.052"
35-2P-FA	19.0 mm	27.4 mm	0.8 mm	1.3 mm	0.748"	1.080"	0.032"	0.052"
36-2P-FA	19.7 mm	28.1 mm	0.8 mm	1.3 mm	0.774"	1.105"	0.032"	0.052"
38-2P-FA	21.0 mm	29.3 mm	0.8 mm	1.3 mm	0.826"	1.155"	0.032"	0.052"
40-2P-FA	22.2 mm	30.7 mm	1.0 mm	1.5 mm	0.874"	1.210"	0.040"	0.060"
42-2P-FA	23.5 mm	32.0 mm	1.0 mm	1.5 mm	0.926"	1.260"	0.040"	0.060"
44-2P-FA	24.8 mm	33.4 mm	1.0 mm	1.5 mm	0.978"	1.315"	0.040"	0.060"
45-2P-FA	25.5 mm	34.0 mm	1.0 mm	1.5 mm	1.004"	1.340"	0.040"	0.060"
48-2P-FA	26.9 mm	36.1 mm	1.0 mm	1.5 mm	1.058"	1.420"	0.040"	0.060"
50-2P-FA	28.2 mm	37.3 mm	1.0 mm	1.5 mm	1.110"	1.470"	0.040"	0.060"
54-2P-FA	30.5 mm	40.0 mm	1.0 mm	1.5 mm	1.200"	1.575"	0.040"	0.060"
60-2P-FA	34.4 mm	43.9 mm	1.0 mm	1.5 mm	1.356"	1.730"	0.040"	0.060"