

3V V-BELT SHEAVES

For 3V V-Belts

2 Grooves

1.094" Face Width


Cast Iron

QD® Style




Part Number	Type	Pitch Dia. "3V" Belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
23V220JA	E1	2.15	2.20	JA	0.500" - 1.250"	1.031	1.000	0.938	0.6
23V235JA	E1	2.30	2.35	JA	0.500" - 1.250"	1.000	1.000	0.906	0.6
23V250JA	E1	2.45	2.50	JA	0.500" - 1.250"	1.000	1.000	0.906	0.7
23V265JA	D1	2.60	2.65	JA	0.500" - 1.250"	0.375	1.000	0.469	0.8
23V280JA	D1	2.75	2.80	JA	0.500" - 1.250"	0.375	1.000	0.469	0.9
23V300JA	D1	2.95	3.00	JA	0.500" - 1.250"	0.375	1.000	0.469	1.2
23V315JA	D1	3.10	3.15	JA	0.500" - 1.250"	0.375	1.000	0.469	1.2
23V335SH	D1	3.30	3.35	SH	0.500" - 1.625"	0.531	1.313	0.313	1.3
23V365SH	D1	3.60	3.65	SH	0.500" - 1.625"	0.531	1.313	0.313	1.5
23V412SH	D1	4.07	4.12	SH	0.500" - 1.625"	0.344	1.313	0.125	2.2
23V450SH	D1	4.45	4.50	SH	0.500" - 1.625"	0.344	1.313	0.125	2.7
23V475SH	D1	4.70	4.75	SH	0.500" - 1.625"	0.344	1.313	0.125	3.1
23V500SH	D1	4.95	5.00	SH	0.500" - 1.625"	0.344	1.313	0.125	3.4
23V530SH	D1	5.25	5.30	SH	0.500" - 1.625"	0.344	1.313	0.125	3.9
23V560SH	D2	5.55	5.60	SH	0.500" - 1.625"	0.344	1.313	0.125	4.0
23V600SH	D2	5.95	6.00	SH	0.500" - 1.625"	0.344	1.313	0.125	4.4
23V650SDS	D2	6.45	6.50	SDS	0.500" - 2.000"	0.344	1.313	0.125	6.0
23V690SDS	D2	6.85	6.90	SDS	0.500" - 2.000"	0.344	1.313	0.125	7.5
23V800SDS	D3	7.95	8.00	SDS	0.500" - 2.000"	0.344	1.313	0.125	8.5
23V1060SK	C3	10.55	10.60	SK	0.500" - 2.625"	0.531	1.938	0.313	12.5
23V1400SK	C3	13.95	14.00	SK	0.500" - 2.625"	0.531	1.938	0.313	19.5
23V1900SK	C3	18.95	19.00	SK	0.500" - 2.625"	0.531	1.938	0.313	27.0
23V2500SF	C3	24.95	25.00	SF	0.500" - 2.938"	0.594	2.063	0.375	38.0

TYPE C

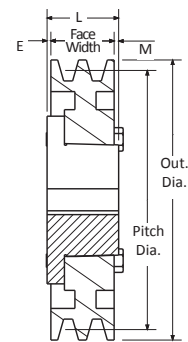

TYPE D

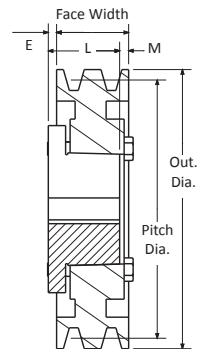

TYPE E

