


3 MM POWERHOUSE™ HTD® TIMING PULLEY BAR STOCK

3 mm Pitch
Aluminum

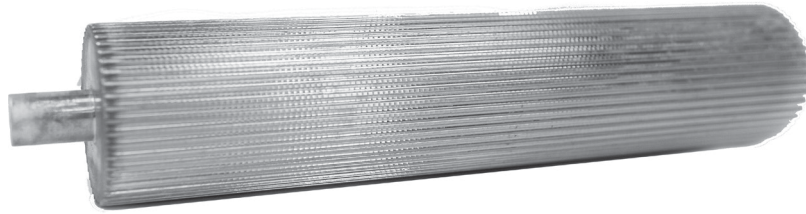

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
9-3M-PS3A	9	8.6 mm	7.8 mm	0.338"	0.308"	0.188"	0.750"	3.000"	3.750"
10-3M-PS3A	10	9.6 mm	8.8 mm	0.376"	0.346"	0.188"	0.750"	3.000"	3.750"
11-3M-PS3A	11	10.5 mm	9.8 mm	0.414"	0.384"	0.250"	0.750"	3.000"	3.750"
12-3M-PS4A	12	11.5 mm	10.7 mm	0.451"	0.421"	0.250"	0.750"	4.000"	4.750"
13-3M-PS4A	13	12.4 mm	11.7 mm	0.489"	0.459"	0.313"	0.750"	4.000"	4.750"
14-3M-PS4A	14	13.4 mm	12.6 mm	0.526"	0.496"	0.313"	0.750"	4.000"	4.750"
15-3M-PS4A	15	14.3 mm	13.6 mm	0.564"	0.534"	0.375"	0.750"	4.000"	4.750"
16-3M-PS5A	16	15.3 mm	14.5 mm	0.602"	0.572"	0.375"	0.750"	5.000"	5.750"
17-3M-PS5A	17	16.2 mm	15.5 mm	0.639"	0.609"	0.500"	0.750"	5.000"	5.750"
18-3M-PS5A	18	17.2 mm	16.4 mm	0.677"	0.647"	0.500"	0.750"	5.000"	5.750"
19-3M-PS5A	19	18.1 mm	17.4 mm	0.714"	0.684"	0.500"	0.750"	5.000"	5.750"
20-3M-PS6A	20	19.1 mm	18.3 mm	0.752"	0.722"	0.500"	0.750"	6.000"	6.750"
21-3M-PS6A	21	20.1 mm	19.3 mm	0.790"	0.760"	0.500"	0.750"	6.000"	6.750"
22-3M-PS6A	22	21.0 mm	20.2 mm	0.827"	0.797"	0.500"	0.750"	6.000"	6.750"
23-3M-PS6A	23	22.0 mm	21.2 mm	0.865"	0.835"	0.500"	0.750"	6.000"	6.750"
24-3M-PS6A	24	22.9 mm	22.1 mm	0.902"	0.872"	0.500"	0.750"	6.000"	6.750"
25-3M-PS6A	25	23.9 mm	23.1 mm	0.940"	0.910"	0.500"	0.750"	6.000"	6.750"
26-3M-PS6A	26	24.8 mm	24.1 mm	0.977"	0.947"	0.500"	0.750"	6.000"	6.750"
27-3M-PS6A	27	25.8 mm	25.0 mm	1.015"	0.985"	0.500"	0.750"	6.000"	6.750"
28-3M-PS6A	28	26.7 mm	26.0 mm	1.053"	1.023"	0.500"	0.750"	6.000"	6.750"
29-3M-PS6A	29	27.7 mm	26.9 mm	1.090"	1.060"	0.500"	0.750"	6.000"	6.750"
30-3M-PS7A	30	28.7 mm	27.9 mm	1.128"	1.098"	0.500"	0.750"	7.000"	7.750"
31-3M-PS7A	31	29.6 mm	28.8 mm	1.165"	1.135"	0.500"	0.750"	7.000"	7.750"
32-3M-PS7A	32	30.6 mm	29.8 mm	1.203"	1.173"	0.500"	0.750"	7.000"	7.750"