

14 MM POWERHOUSE MX™ BELTS

(Compatible with Poly Chain® GT® sprockets)


Standard Widths:

20 mm, 37 mm, 68 mm, 90 mm, 125 mm

Polyurethane Construction

Carbon Tensile Reinforcements

(Note: Custom belt widths are available upon request.)

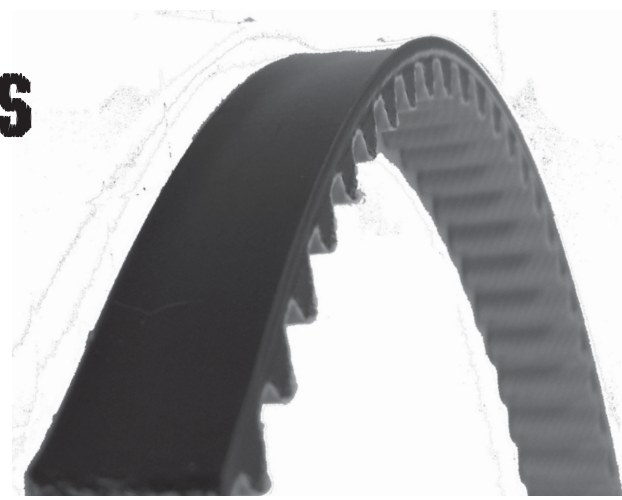

Part Number	No. of Teeth	Pitch Length (mm)
994-14MX	71	994.0
1120-14MX	80	1120.0
1190-14MX	85	1190.0
1260-14MX	90	1260.0
1400-14MX	100	1400.0
1568-14MX	112	1568.0
1610-14MX	115	1610.0
1750-14MX	125	1750.0
1890-14MX	135	1890.0

Part Number	No. of Teeth	Pitch Length (mm)
1960-14MX	140	1960.0
2100-14MX	150	2100.0
2240-14MX	160	2240.0
2310-14MX	165	2310.0
2380-14MX	170	2380.0
2450-14MX	175	2450.0
2520-14MX	180	2520.0
2590-14MX	185	2590.0
2660-14MX	190	2660.0

Part Number	No. of Teeth	Pitch Length (mm)
2800-14MX	200	2800.0
3136-14MX	224	3136.0
3304-14MX	236	3304.0
3360-14MX	240	3360.0
3500-14MX	250	3500.0
3850-14MX	275	3850.0
3920-14MX	280	3920.0
4326-14MX	309	4326.0
4410-14MX	315	4410.0

Polyurethane 14 mm POWERHOUSE MX™ timing belt part numbers can be determined as follows:
Pitch Length Code + -14MX- + Width Code



Our veteran sales staff is available to help you make informed decisions on which precision mechanical or power transmission components are best for your project.
Call us today!