

T5 TIMING BELTS

5 mm Pitch


Standard Widths:

6 mm, 8 mm, 10 mm,
12 mm, 16 mm, 20 mm, 25 mm

Polyurethane Construction

Steel Reinforcements

(Note: Custom belt widths are available upon request.)

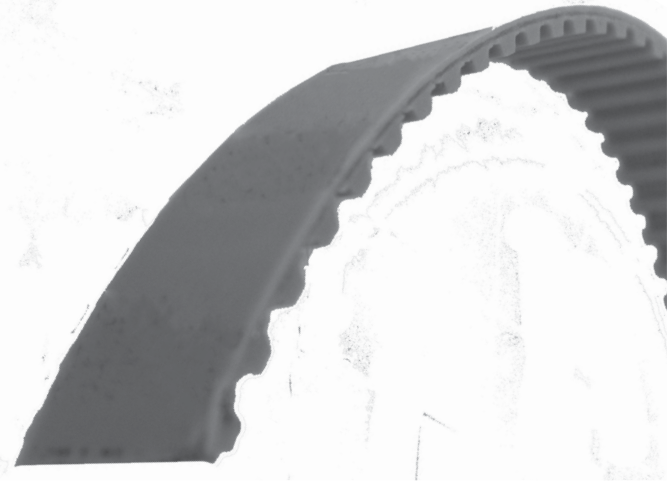

Part Number	No. of Teeth	Pitch Length (mm)
T5/165	33	165.0
T5/185	37	185.0
T5/200	40	200.0
T5/215	43	215.0
T5/220	44	220.0
T5/225	45	225.0
T5/245	49	245.0
T5/250	50	250.0
T5/255	51	255.0
T5/260	52	260.0
T5/270	54	270.0
T5/275	55	275.0
T5/280	56	280.0
T5/295	59	295.0
T5/300	60	300.0
T5/305	61	305.0
T5/320	64	320.0
T5/325	65	325.0
T5/330	66	330.0
T5/340	68	340.0
T5/350	70	350.0
T5/355	71	355.0
T5/360	72	360.0
T5/365	73	365.0
T5/375	75	375.0
T5/390	78	390.0
T5/400	80	400.0

Part Number	No. of Teeth	Pitch Length (mm)
T5/410	82	410.0
T5/420	84	420.0
T5/425	85	425.0
T5/430	86	430.0
T5/440	88	440.0
T5/445	89	445.0
T5/450	90	450.0
T5/455	91	455.0
T5/460	92	460.0
T5/475	95	475.0
T5/480	96	480.0
T5/500	100	500.0
T5/510	102	510.0
T5/525	105	525.0
T5/545	109	545.0
T5/550	110	550.0
T5/560	112	560.0
T5/575	115	575.0
T5/590	118	590.0
T5/600	120	600.0
T5/610	122	610.0
T5/620	124	620.0
T5/625	125	625.0
T5/630	126	630.0
T5/640	128	640.0
T5/650	130	650.0
T5/660	132	660.0

Part Number	No. of Teeth	Pitch Length (mm)
T5/675	165	675.0
T5/690	138	690.0
T5/700	140	700.0
T5/720	144	720.0
T5/725	145	725.0
T5/750	150	750.0
T5/780	156	780.0
T5/800	160	800.0
T5/815	163	815.0
T5/840	168	840.0
T5/850	170	850.0
T5/860	172	860.0
T5/900	180	900.0
T5/940	188	940.0
T5/990	198	990.0
T5/1000	200	1000.0
T5/1075	215	1075.0
T5/1100	220	1100.0
T5/1115	223	1115.0
T5/1140	228	1140.0
T5/1215	243	1215.0
T5/1315	263	1315.0
T5/1350	270	1350.0
T5/1380	276	1380.0
T5/1440	288	1440.0

Polyurethane T5 timing belt part numbers can be determined as follows:
Width Code + T5/ + Pitch Length Code