


MXL TIMING PULLEY FLANGES

0.080" / 2.03 mm Pitch
Aluminum

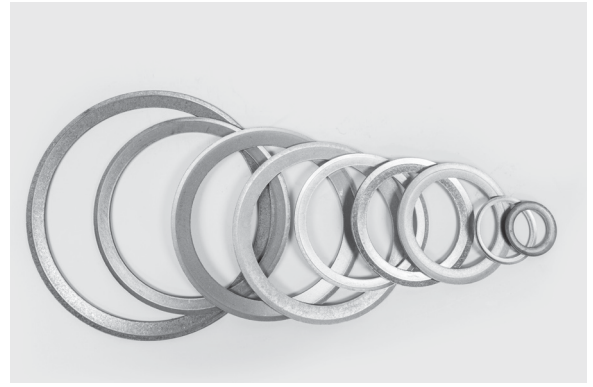

| Part Number | Metric | | | | Inch | | | |
|-------------|-----------------|------------------|-----------------|--------------------------|-----------------|------------------|-----------------|--------------------------|
| | Inside Diameter | Outside Diameter | Stock Thickness | Overall Formed Thickness | Inside Diameter | Outside Diameter | Stock Thickness | Overall Formed Thickness |
| 10MP-FA | 4.8 mm | 10.8 mm | 0.6 mm | 1.1 mm | 0.188" | 0.425" | 0.025" | 0.045" |
| 11MP-FA | 5.4 mm | 11.4 mm | 0.6 mm | 1.1 mm | 0.214" | 0.450" | 0.025" | 0.045" |
| 12MP-FA | 5.5 mm | 12.2 mm | 0.6 mm | 1.1 mm | 0.218" | 0.480" | 0.025" | 0.045" |
| 13MP-FA | 6.2 mm | 12.8 mm | 0.6 mm | 1.1 mm | 0.244" | 0.505" | 0.025" | 0.045" |
| 14MP-FA | 6.9 mm | 13.5 mm | 0.6 mm | 1.1 mm | 0.270" | 0.530" | 0.025" | 0.045" |
| 15MP-FA | 7.5 mm | 14.1 mm | 0.6 mm | 1.1 mm | 0.296" | 0.555" | 0.025" | 0.045" |
| 16MP-FA | 8.2 mm | 14.7 mm | 0.6 mm | 1.1 mm | 0.322" | 0.580" | 0.025" | 0.045" |
| 18MP-FA | 9.5 mm | 16.1 mm | 0.8 mm | 1.3 mm | 0.374" | 0.635" | 0.032" | 0.052" |
| 20MP-FA | 10.0 mm | 17.4 mm | 0.8 mm | 1.3 mm | 0.394" | 0.685" | 0.032" | 0.052" |
| 21MP-FA | 10.8 mm | 18.0 mm | 0.8 mm | 1.3 mm | 0.426" | 0.710" | 0.032" | 0.052" |
| 22MP-FA | 11.5 mm | 18.8 mm | 0.8 mm | 1.3 mm | 0.452" | 0.740" | 0.032" | 0.052" |
| 24MP-FA | 12.8 mm | 20.1 mm | 0.8 mm | 1.3 mm | 0.504" | 0.790" | 0.032" | 0.052" |
| 25MP-FA | 13.5 mm | 20.7 mm | 0.8 mm | 1.3 mm | 0.530" | 0.815" | 0.032" | 0.052" |
| 26MP-FA | 14.1 mm | 21.3 mm | 0.8 mm | 1.3 mm | 0.556" | 0.840" | 0.032" | 0.052" |
| 28MP-FA | 14.6 mm | 22.7 mm | 0.8 mm | 1.3 mm | 0.574" | 0.895" | 0.032" | 0.052" |
| 30MP-FA | 15.9 mm | 24.0 mm | 0.8 mm | 1.3 mm | 0.626" | 0.945" | 0.032" | 0.052" |
| 32MP-FA | 17.2 mm | 25.4 mm | 0.8 mm | 1.3 mm | 0.678" | 1.000" | 0.032" | 0.052" |
| 33MP-FA | 17.9 mm | 26.0 mm | 0.8 mm | 1.3 mm | 0.704" | 1.025" | 0.032" | 0.052" |
| 34MP-FA | 18.3 mm | 26.7 mm | 0.8 mm | 1.3 mm | 0.722" | 1.050" | 0.032" | 0.052" |
| 35MP-FA | 19.0 mm | 27.4 mm | 0.8 mm | 1.3 mm | 0.748" | 1.080" | 0.032" | 0.052" |
| 36MP-FA | 19.7 mm | 28.1 mm | 0.8 mm | 1.3 mm | 0.774" | 1.105" | 0.032" | 0.052" |
| 38MP-FA | 21.0 mm | 29.3 mm | 0.8 mm | 1.3 mm | 0.826" | 1.155" | 0.032" | 0.052" |
| 40MP-FA | 22.2 mm | 30.7 mm | 1.0 mm | 1.5 mm | 0.874" | 1.210" | 0.040" | 0.060" |
| 42MP-FA | 23.5 mm | 32.0 mm | 1.0 mm | 1.5 mm | 0.926" | 1.260" | 0.040" | 0.060" |
| 44MP-FA | 24.8 mm | 33.4 mm | 1.0 mm | 1.5 mm | 0.978" | 1.315" | 0.040" | 0.060" |
| 45MP-FA | 25.5 mm | 34.0 mm | 1.0 mm | 1.5 mm | 1.004" | 1.340" | 0.040" | 0.060" |
| 48MP-FA | 26.9 mm | 36.1 mm | 1.0 mm | 1.5 mm | 1.058" | 1.420" | 0.040" | 0.060" |
| 50MP-FA | 28.2 mm | 37.3 mm | 1.0 mm | 1.5 mm | 1.110" | 1.470" | 0.040" | 0.060" |
| 54MP-FA | 30.5 mm | 40.0 mm | 1.0 mm | 1.5 mm | 1.200" | 1.575" | 0.040" | 0.060" |
| 60MP-FA | 34.4 mm | 43.9 mm | 1.0 mm | 1.5 mm | 1.356" | 1.730" | 0.040" | 0.060" |