

POWERHOUSE MX™

TIMING PULLEYS

(Compatible with Poly Chain® GT® Carbon belts)

14 mm Pitch



For 90 mm Wide Belts

Iron

Black Oxide Plating



Part Number	No. of Teeth	Type	Pitch Dia. (in)	Out. Dia. (in)	Flange Dia. (in)	Bore/Bushing	Face Width (in)	Overall Length (in)
28-14MX90-6FS16	28	6F	4.912	4.802	5.562	1.500	4.203	5.141
29-14MX90-6FS16	29	6F	5.088	4.978	5.562	1.500	4.203	5.000
30-14MX90-6FS16	30	6F	5.263	5.153	5.763	1.500	4.203	5.000
31-14MX90-6FS16	31	6F	5.439	5.329	6.124	1.500	4.203	5.000
32-14MX90-6FS16	32	6F	5.614	5.504	6.124	1.500	4.203	5.000
33-14MX90-6FS16	33	6F	5.790	5.68	6.465	1.500	4.203	5.203
34-14MX90-6FS16	34	6F	5.965	5.855	6.465	1.500	4.203	5.203
35-14MX90-3020	35	A1F	6.141	6.031	6.816	3020	4.203	4.203
35-14MX90-6FS16	35	6F	6.141	6.031	6.816	1.500	4.203	4.203
36-14MX90-3020	36	A1F	6.316	6.206	6.816	3020	4.203	4.203
36-14MX90-6FS16	36	6F	6.316	6.206	6.816	1.500	4.203	4.203
37-14MX90-3020	37	A1F	6.492	6.382	7.167	3020	4.203	4.203
37-14MX90-6FS16	37	6F	6.492	6.382	7.167	1.500	4.203	4.203
38-14MX90-3020	38	A1F	6.667	6.557	7.167	3020	4.203	4.203
38-14MX90-6FS16	38	6F	6.667	6.557	7.167	1.500	4.203	4.203
39-14MX90-3020	39	A1F	6.842	6.732	7.518	3020	4.203	4.203
39-14MX90-6FS16	39	6F	6.842	6.732	7.518	1.500	4.203	4.203
40-14MX90-3020	40	A1F	7.018	6.908	7.518	3020	4.203	4.203
40-14MX90-6FS16	40	6F	7.018	6.908	7.518	1.500	4.203	4.203
43-14MX90-3525	43	A1F	7.544	7.434	8.395	3525	4.203	4.203
45-14MX90-3525	45	A1F	7.895	7.785	8.395	3525	4.203	4.203
48-14MX90-3525	48	A1F	8.421	8.311	8.941	3525	4.203	4.203
50-14MX90-3525	50	A1F	8.772	8.662	9.292	3525	4.203	4.203
53-14MX90-3525	53	A1F	9.299	9.189	9.687	3525	4.203	4.203
56-14MX90-4030	56	A1F	9.825	9.715	10.355	4030	4.203	4.203
60-14MX90-4030	60	A1F	10.527	10.417	11.067	4030	4.203	4.203
63-14MX90-4030	63	A1F	11.053	10.943	11.750	4030	4.203	4.203
67-14MX90-4030	67	A1F	11.755	11.645	12.500	4030	4.203	4.203

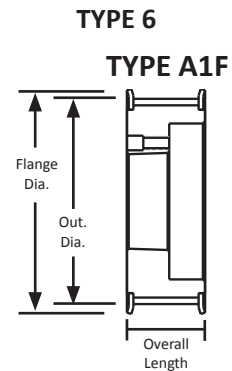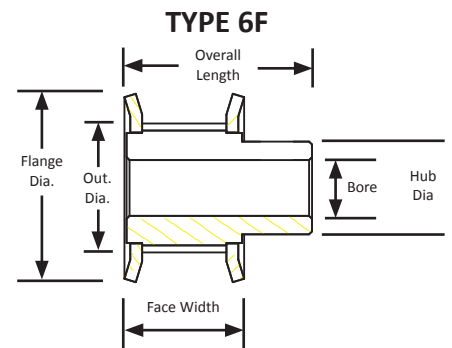

For matching Taper-Lock® bushings, see page 329.