


# 5 MM POWERHOUSE™ HTD® TIMING PULLEY BAR STOCK

5 mm Pitch  
Aluminum

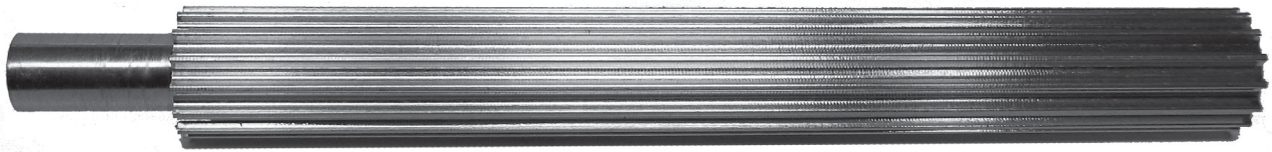

Timing Pulley Stock

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
12-5M-PS6A	12	19.1 mm	18.0 mm	0.752"	0.707"	0.500"	0.875"	6.000"	6.875"
13-5M-PS6A	13	20.7 mm	19.6 mm	0.815"	0.770"	0.500"	0.875"	6.000"	6.875"
14-5M-PS7A	14	22.3 mm	21.1 mm	0.877"	0.832"	0.500"	1.000"	7.000"	8.000"
15-5M-PS7A	15	23.9 mm	22.7 mm	0.940"	0.895"	0.500"	1.000"	7.000"	8.000"
16-5M-PS7A	16	25.5 mm	24.3 mm	1.003"	0.958"	0.500"	1.000"	7.000"	8.000"
17-5M-PS7A	17	27.1 mm	25.9 mm	1.065"	1.020"	0.500"	1.000"	7.000"	8.000"
18-5M-PS8A	18	28.7 mm	27.5 mm	1.128"	1.083"	0.500"	1.000"	8.000"	9.000"
19-5M-PS8A	19	30.3 mm	29.1 mm	1.191"	1.146"	0.500"	1.000"	8.000"	9.000"
20-5M-PS8A	20	31.8 mm	30.7 mm	1.253"	1.208"	0.500"	1.000"	8.000"	9.000"
21-5M-PS8A	21	33.4 mm	32.3 mm	1.316"	1.271"	0.500"	1.000"	8.000"	9.000"
22-5M-PS8A	22	35.0 mm	33.9 mm	1.379"	1.334"	0.500"	1.000"	8.000"	9.000"
23-5M-PS8A	23	36.6 mm	35.5 mm	1.441"	1.396"	0.500"	1.000"	8.000"	9.000"
24-5M-PS8A	24	38.2 mm	37.1 mm	1.504"	1.459"	0.500"	1.000"	8.000"	9.000"
25-5M-PS8A	25	39.8 mm	38.6 mm	1.566"	1.521"	0.500"	1.000"	8.000"	9.000"
26-5M-PS8A	26	41.4 mm	40.2 mm	1.629"	1.584"	0.500"	1.000"	8.000"	9.000"
27-5M-PS8A	27	43.0 mm	41.8 mm	1.692"	1.647"	0.500"	1.000"	8.000"	9.000"
28-5M-PS8A	28	44.6 mm	43.4 mm	1.754"	1.709"	0.500"	1.000"	8.000"	9.000"
29-5M-PS8A	29	46.2 mm	45.0 mm	1.817"	1.772"	0.500"	1.000"	8.000"	9.000"
30-5M-PS8A	30	47.8 mm	46.6 mm	1.880"	1.835"	0.500"	1.000"	8.000"	9.000"
31-5M-PS8A	31	49.3 mm	48.2 mm	1.942"	1.897"	0.750"	1.000"	8.000"	9.000"
32-5M-PS8A	32	50.9 mm	49.8 mm	2.005"	1.960"	0.750"	1.000"	8.000"	9.000"
33-5M-PS8A	33	52.5 mm	51.4 mm	2.068"	2.023"	0.750"	1.000"	8.000"	9.000"
34-5M-PS8A	34	54.1 mm	53.0 mm	2.130"	2.085"	0.750"	1.000"	8.000"	9.000"
35-5M-PS8A	35	55.7 mm	54.6 mm	2.193"	2.148"	0.750"	1.000"	8.000"	9.000"
36-5M-PS8A	36	57.3 mm	56.2 mm	2.256"	2.211"	0.750"	1.000"	8.000"	9.000"
38-5M-PS8A	38	60.5 mm	59.3 mm	2.381"	2.336"	0.750"	1.000"	8.000"	9.000"