

5V V-BELT SHEAVES

For 5V V-Belts

3 Grooves

2.375" Face Width


Cast Iron

QD® Style




Part Number	Bushing	Bore Range	Type	Pitch Dia. "5V" Belts (in)	Out. Dia. (in)	E	L	M	Wt. Ea. (Lbs.)
35V440SDS	SDS	0.500" - 2.000"	E1	4.30	4.40	1.719	1.313	0.656	6.5
35V465SDS	SDS	0.500" - 2.000"	E1	4.55	4.65	1.719	1.313	0.656	7.6
35V490SDS	SDS	0.500" - 2.000"	A1	4.80	4.90	0.406	1.313	0.656	7.8
35V520SDS	SDS	0.500" - 2.000"	A1	5.10	5.20	0.406	1.313	0.656	8.0
35V550SDS	SDS	0.500" - 2.000"	A1	5.40	5.50	0.406	1.313	0.656	8.2
35V590SDS	SDS	0.500" - 2.000"	A1	5.80	5.90	0.406	1.313	0.656	8.6
35V630SK	SK	0.500" - 2.625"	A1	6.20	6.30	0.281	1.938	0.156	10.4
35V670SK	SK	0.500" - 2.625"	A1	6.60	6.70	0.281	1.938	0.156	11.7
35V710SF	SF	0.500" - 2.938"	A1	7.00	7.10	0.156	2.063	0.156	12.7
35V750SF	SF	0.500" - 2.938"	A1	7.40	7.50	0.156	2.063	0.156	15.0
35V800SF	SF	0.500" - 2.938"	A1	7.90	8.00	0.156	2.063	0.156	16.5
35V850SF	SF	0.500" - 2.938"	A3	8.40	8.50	0.156	2.063	0.156	18.0
35V900SF	SF	0.500" - 2.938"	A3	8.90	9.00	0.156	2.063	0.156	19.8
35V925SF	SF	0.500" - 2.938"	A3	9.15	9.25	0.156	2.063	0.156	20.7
35V975SF	SF	0.500" - 2.938"	A3	9.65	9.75	0.156	2.063	0.156	22.6
35V1030SF	SF	0.500" - 2.938"	A3	10.20	10.30	0.156	2.063	0.156	24.6
35V1090SF	SF	0.500" - 2.938"	A3	10.80	10.90	0.156	2.063	0.156	26.7
35V1130SF	SF	0.500" - 2.938"	A3	11.20	11.30	0.156	2.063	0.156	28.2
35V1180SF	SF	0.500" - 2.938"	A3	11.70	11.80	0.156	2.063	0.156	29.7
35V1250E	E	0.875" - 3.500"	D3	12.40	12.50	0.406	2.750	0.031	34.0
35V1320E	E	0.875" - 3.500"	D3	13.10	13.20	0.406	2.750	0.031	35.0
35V1400E	E	0.875" - 3.500"	D3	13.90	14.00	0.406	2.750	0.031	37.0
35V1500E	E	0.875" - 3.500"	D3	14.90	15.00	0.406	2.750	0.031	38.0
35V1600E	E	0.875" - 3.500"	D3	15.90	16.00	0.406	2.750	0.031	39.2
35V1870E	E	0.875" - 3.500"	D3	16.60	18.70	0.406	2.750	0.031	47.2
35V2120E	E	0.875" - 3.500"	D3	21.10	21.20	0.406	2.750	0.031	55.0
35V2360E	E	0.875" - 3.500"	D3	23.50	23.60	0.406	2.750	0.031	70.2
35V2800E	E	0.875" - 3.500"	D3	27.90	28.00	0.406	2.750	0.031	86.5
35V3150F	F	1.000" - 4.000"	C3	31.40	31.50	0.781	3.750	0.594	116.0
35V3750F	F	1.000" - 4.000"	C3	37.40	37.50	0.781	3.750	0.594	141.0
35V5000F	F	1.000" - 4.000"	C3	49.90	50.00	0.781	3.750	0.594	211.0


TYPE A

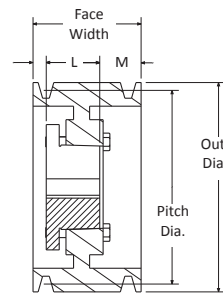

TYPE C

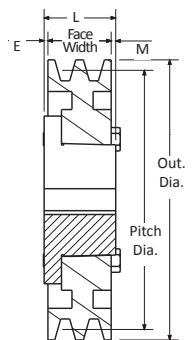

TYPE D

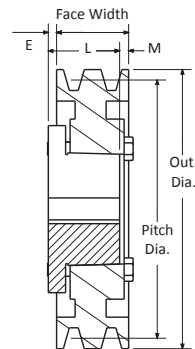

TYPE E

