

14 MM POWERHOUSE™ HTD® BELTS

Standard Widths:

40 mm, 55 mm, 85 mm, 115 mm, 170 mm

Neoprene Construction

Fiberglass Reinforcements

(Note: Custom belt widths are available upon request.)



Timing Belts



Part Number	No. of Teeth	Pitch Length (mm)
784-14M	56	784.0
826-14M	59	826.0
924-14M	66	924.0
966-14M	69	966.0
1092-14M	78	1092.0
1148-14M	82	1148.0
1190-14M	85	1190.0
1330-14M	95	1330.0
1344-14M	96	1344.0
1358-14M	97	1358.0
1400-14M	100	1400.0
1456-14M	104	1456.0
1470-14M	105	1470.0
1512-14M	108	1512.0
1540-14M	110	1540.0
1554-14M	111	1554.0
1568-14M	112	1568.0
1610-14M	115	1610.0
1638-14M	117	1638.0


Part Number	No. of Teeth	Pitch Length (mm)
1652-14M	118	1652.0
1680-14M	120	1680.0
1736-14M	124	1736.0
1778-14M	127	1778.0
1820-14M	130	1820.0
1862-14M	133	1862.0
1890-14M	135	1890.0
1904-14M	136	1904.0
1918-14M	137	1918.0
1932-14M	138	1932.0
1946-14M	139	1946.0
1974-14M	141	1974.0
2002-14M	143	2002.0
2044-14M	146	2044.0
2100-14M	150	2100.0
2198-14M	157	2198.0
2310-14M	165	2310.0
2450-14M	175	2450.0
2590-14M	185	2590.0

Part Number	No. of Teeth	Pitch Length (mm)
2660-14M	190	2660.0
2800-14M	200	2800.0
2940-14M	210	2940.0
3150-14M	225	3150.0
3360-14M	240	3360.0
3500-14M	250	3500.0
3850-14M	275	3850.0
3920-14M	280	3920.0
4004-14M	286	4004.0
4326-14M	309	4326.0
4578-14M	327	4578.0
4956-14M	354	4956.0
5320-14M	380	5320.0
5530-14M	395	5530.0
5740-14M	410	5740.0
5880-14M	420	5880.0
6160-14M	440	6160.0
6860-14M	490	6860.0

Neoprene 14 mm POWERHOUSE™ HTD® timing belt part numbers can be determined as follows:
Pitch Length Code + -14M- + Width Code



For Powerhouse™ ACHE sprockets, see page 174.

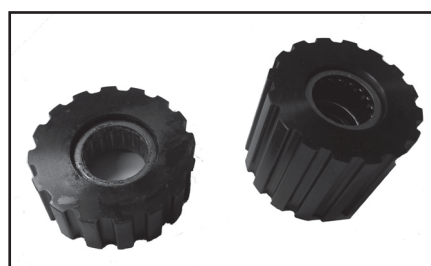

For idler pulleys, see page 366.



For matching QD® bushings, see page 324.