

# A-B COMBINATION V-BELT SHEAVES

For use with "A" or "B" Section Belts

3 Grooves

2.500" Face Width


Cast Iron

QD® Style




Part Number	Type	Pitch Dia. "A" belts (in)	Pitch Dia. "B" belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
3B34SH	E1	3.0	3.4	3.75	SH	0.500" - 1.625"	1.844	1.313	0.656	4.4
3B36SH	D1	3.2	3.6	3.95	SH	0.500" - 1.625"	0.469	1.313	1.656	4.7
3B38SH	D1	3.4	3.8	4.15	SH	0.500" - 1.625"	0.469	1.313	1.656	5.3
3B40SH	D1	3.6	4.0	4.35	SH	0.500" - 1.625"	0.469	1.313	1.656	5.6
3B42SH	D1	3.8	4.2	4.55	SH	0.500" - 1.625"	0.469	1.313	1.656	5.9
3B44SH	D1	4.0	4.4	4.75	SH	0.500" - 1.625"	0.469	1.313	1.656	6.3
3B46SD	A1	4.2	4.6	4.95	SD	0.500" - 1.938"	0.406	1.813	0.281	6.7
3B48SD	A1	4.4	4.8	5.15	SD	0.500" - 1.938"	0.406	1.813	0.281	7.1
3B50SD	A1	4.6	5.0	5.35	SD	0.500" - 1.938"	0.406	1.813	0.281	7.4
3B52SD	A1	4.8	5.2	5.55	SD	0.500" - 1.938"	0.406	1.813	0.281	7.8
3B54SD	A1	5.0	5.4	5.75	SD	0.500" - 1.938"	0.406	1.813	0.281	8.2
3B56SD	A1	5.2	5.6	5.95	SD	0.500" - 1.938"	0.406	1.813	0.281	8.5
3B58SD	A1	5.4	5.8	6.15	SD	0.500" - 1.938"	0.406	1.813	0.281	8.8
3B60SD	A1	5.6	6.0	6.35	SD	0.500" - 1.938"	0.406	1.813	0.281	9.1
3B62SD	A1	5.8	6.2	6.55	SD	0.500" - 1.938"	0.406	1.813	0.281	9.4
3B64SD	A1	6.0	6.4	6.75	SD	0.500" - 1.938"	0.406	1.813	0.281	9.7
3B66SD	A1	6.2	6.6	6.95	SD	0.500" - 1.938"	0.406	1.813	0.281	10.0
3B68SD	B3	6.4	6.8	7.15	SD	0.500" - 1.938"	0.406	1.813	0.281	10.5
3B70SK	D1	6.6	7.0	7.35	SK	0.500" - 2.500"	0.094	1.938	0.656	11.0
3B74SK	D3	7.0	7.4	7.75	SK	0.500" - 2.500"	0.094	1.938	0.656	12.0
3B80SK	D3	7.6	8.0	8.35	SK	0.500" - 2.500"	0.094	1.938	0.656	12.5
3B86SK	D3	8.2	8.6	8.95	SK	0.500" - 2.500"	0.094	1.938	0.656	13.0
3B94SK	D3	9.0	9.4	9.75	SK	0.500" - 2.625"	0.094	1.938	0.656	16.0
3B110SK	D3	10.6	11.0	11.35	SK	0.500" - 2.625"	0.094	1.938	0.656	19.0
3B124SK	D3	12.0	12.4	12.75	SK	0.500" - 2.625"	0.094	1.938	0.656	24.0
3B136SK	D3	13.2	13.6	13.95	SK	0.500" - 2.625"	0.094	1.938	0.656	27.0
3B154SK	D3	15.0	15.4	15.75	SK	0.500" - 2.625"	0.094	1.938	0.656	30.0
3B160SK	D3	15.6	16.0	16.35	SK	0.500" - 2.625"	0.094	1.938	0.656	33.0
3B184SK	D3	18.0	18.4	18.75	SK	0.500" - 2.625"	0.094	1.938	0.656	38.0
3B200SF	D3	19.6	20.0	20.35	SF	0.500" - 2.938"	0.219	2.063	0.656	43.0
3B250SF	D3	24.6	25.0	25.35	SF	0.500" - 2.938"	0.219	2.063	0.656	54.0
3B300SF	D3	29.6	30.0	30.35	SF	0.500" - 2.938"	0.219	2.063	0.656	67.0
3B380E	D3	37.6	38.0	38.35	E	0.875" - 3.500"	0.531	2.75	0.281	90.0


TYPE A

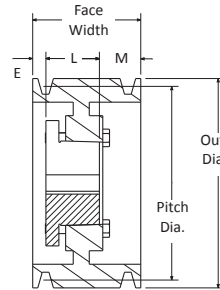

TYPE B

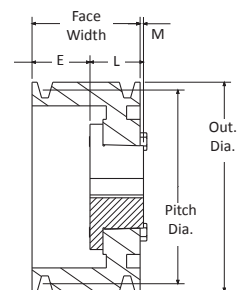

TYPE D

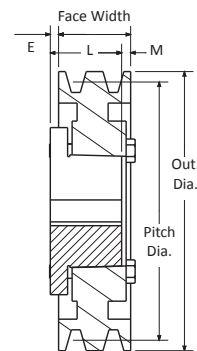

TYPE E

