


MXL TIMING PULLEY BAR STOCK

0.080" / 2.03 mm Pitch
Aluminum

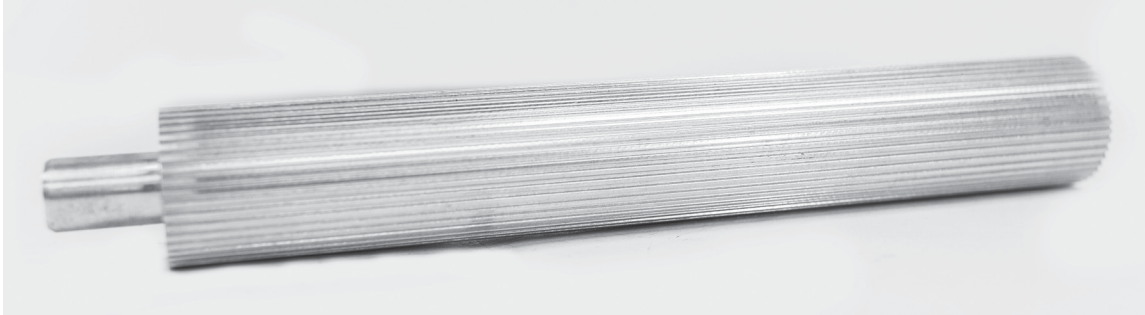

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
35MP-PS6A	35	22.6 mm	22.1 mm	0.891"	0.871"	0.500"	0.750"	6.000"	6.750"
36MP-PS6A	36	23.3 mm	22.8 mm	0.917"	0.897"	0.500"	0.750"	6.000"	6.750"
37MP-PS6A	37	23.9 mm	23.4 mm	0.942"	0.922"	0.500"	0.750"	6.000"	6.750"
38MP-PS6A	38	24.6 mm	24.1 mm	0.968"	0.948"	0.500"	0.750"	6.000"	6.750"
39MP-PS6A	39	25.2 mm	24.7 mm	0.993"	0.973"	0.500"	0.750"	6.000"	6.750"
40MP-PS7A	40	25.9 mm	25.4 mm	1.019"	0.999"	0.500"	0.750"	7.000"	7.750"
42MP-PS7A	42	27.2 mm	26.7 mm	1.070"	1.050"	0.500"	0.750"	7.000"	7.750"
44MP-PS7A	44	28.4 mm	27.9 mm	1.120"	1.100"	0.500"	0.750"	7.000"	7.750"
45MP-PS7A	45	29.1 mm	28.6 mm	1.146"	1.126"	0.500"	0.750"	7.000"	7.750"
48MP-PS7A	48	31.0 mm	30.5 mm	1.222"	1.202"	0.500"	0.750"	7.000"	7.750"
49MP-PS7A	49	31.7 mm	31.2 mm	1.248"	1.228"	0.500"	0.750"	7.000"	7.750"
50MP-PS7A	50	32.3 mm	31.8 mm	1.273"	1.253"	0.500"	0.750"	7.000"	7.750"
51MP-PS7A	51	33.0 mm	32.5 mm	1.299"	1.279"	0.500"	0.750"	7.000"	7.750"
52MP-PS7A	52	33.6 mm	33.1 mm	1.324"	1.304"	0.500"	0.750"	7.000"	7.750"
54MP-PS7A	54	34.9 mm	34.4 mm	1.375"	1.355"	0.500"	0.750"	7.000"	7.750"
55MP-PS7A	55	35.6 mm	35.1 mm	1.401"	1.381"	0.500"	0.750"	7.000"	7.750"
56MP-PS7A	56	36.2 mm	35.7 mm	1.426"	1.406"	0.500"	0.750"	7.000"	7.750"
57MP-PS7A	57	36.9 mm	36.3 mm	1.451"	1.431"	0.500"	0.750"	7.000"	7.750"
60MP-PS8A	60	38.8 mm	38.3 mm	1.528"	1.508"	0.500"	0.750"	8.000"	8.750"
64MP-PS8A	64	41.4 mm	40.9 mm	1.630"	1.610"	0.500"	0.750"	8.000"	8.750"
65MP-PS8A	65	42.0 mm	41.5 mm	1.655"	1.635"	0.500"	0.750"	8.000"	8.750"
66MP-PS8A	66	42.7 mm	42.2 mm	1.681"	1.661"	0.500"	0.750"	8.000"	8.750"
70MP-PS8A	70	45.3 mm	44.8 mm	1.783"	1.763"	0.500"	0.750"	8.000"	8.750"
72MP-PS8A	72	46.6 mm	46.1 mm	1.833"	1.813"	0.500"	0.750"	8.000"	8.750"
75MP-PS8A	75	48.5 mm	48.0 mm	1.910"	1.890"	0.500"	0.750"	8.000"	8.750"