

# 5V V-BELT SHEAVES

For 5V V-Belts

4 Grooves

3.063" Face Width


Cast Iron

QD® Style




Part Number	Bushing	Bore Range	Type	Pitch Dia. "5V" Belts (in)	Out. Dia. (in)	E	L	M	Wt. Ea. (Lbs.)
45V440SD	SD	0.500" - 2.000"	E1	4.30	4.40	1.906	1.813	0.656	7.5
45V465SD	SD	0.500" - 2.000"	E1	4.55	4.65	1.906	1.813	0.656	8.0
45V490SD	SD	0.500" - 2.000"	A1	4.80	4.90	0.656	1.813	0.594	8.5
45V520SD	SD	0.500" - 2.000"	A1	5.10	5.20	0.656	1.813	0.594	8.8
45V550SD	SD	0.500" - 2.000"	A1	5.40	5.50	0.656	1.813	0.594	9.3
45V590SD	SD	0.500" - 2.000"	A1	5.80	5.90	0.656	1.813	0.594	10.1
45V630SK	SK	0.500" - 2.625"	A1	6.20	6.30	0.531	1.938	0.594	11.8
45V670SK	SK	0.500" - 2.625"	A1	6.60	6.70	0.531	1.938	0.594	13.6
45V710SF	SF	0.500" - 2.938"	A1	7.00	7.10	0.219	2.063	0.781	14.9
45V750SF	SF	0.500" - 2.938"	A1	7.40	7.50	0.219	2.063	0.781	17.0
45V800E	E	0.500" - 2.938"	B1	7.90	8.00	0.344	2.750	0.031	18.8
45V850E	E	0.875" - 3.500"	B1	8.40	8.50	0.344	2.750	0.031	21.9
45V900E	E	0.875" - 3.500"	B1	8.90	9.00	0.344	2.750	0.031	24.2
45V925E	E	0.875" - 3.500"	B1	9.15	9.25	0.344	2.750	0.031	25.8
45V975E	E	0.875" - 3.500"	B1	9.65	9.75	0.344	2.750	0.031	28.2
45V1030E	E	0.875" - 3.500"	B1	10.20	10.30	0.344	2.750	0.031	29.8
45V1090E	E	0.875" - 3.500"	B2	10.80	10.90	0.344	2.750	0.031	30.6
45V1130E	E	0.875" - 3.500"	A3	11.20	11.30	0.281	2.750	0.031	31.9
45V1180E	E	0.875" - 3.500"	B2	11.70	11.80	0.344	2.750	0.031	33.0
45V1250E	E	0.875" - 3.500"	A3	12.40	12.50	0.281	2.750	0.031	36.4
45V1320E	E	0.875" - 3.500"	A3	13.10	13.20	0.281	2.750	0.031	38.2
45V1400E	E	0.875" - 3.500"	A3	13.90	14.00	0.281	2.750	0.031	40.2
45V1500E	E	0.875" - 3.500"	A3	14.90	15.00	0.281	2.750	0.031	43.5
45V1600E	E	0.875" - 3.500"	A3	15.90	16.00	0.281	2.750	0.031	44.6
45V1870E	E	0.875" - 3.500"	A3	18.60	18.70	0.094	2.750	0.219	53.6
45V2120E	E	0.875" - 3.500"	A3	21.10	21.20	0.094	2.750	0.219	62.5
45V2360F	F	1.000" - 4.000"	C3	23.50	23.60	0.469	3.750	0.219	83.5
45V2800F	F	1.000" - 4.000"	C3	27.90	28.00	0.469	3.750	0.219	126.0
45V3150F	F	1.000" - 4.000"	C3	31.40	31.50	0.469	3.750	0.219	148.0
45V3750F	F	1.000" - 4.000"	C3	37.40	37.50	0.469	3.750	0.219	170.0
45V5000J	J	1.500" - 4.500"	C3	49.90	50.00	0.750	4.625	0.813	248.0


TYPE A

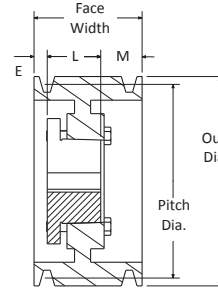

TYPE B

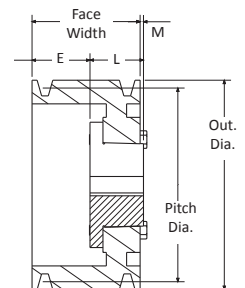

TYPE C

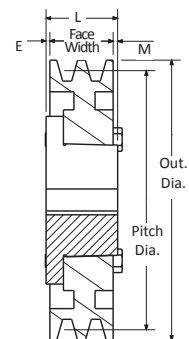

TYPE E

