

A-B COMBINATION V-BELT SHEAVES

For use with "A" or "B" Section Belts

4 Grooves

3.250" Face Width


Cast Iron

QD® Style




Part Number	Type	Pitch Dia. "A" belts (in)	Pitch Dia. "B" belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
4B34SD	E1	3	3.4	3.75	SD	0.500" - 2.000"	2.469	1.813	1.031	5.5
4B36SD	E1	3.2	3.6	3.95	SD	0.500" - 2.000"	2.469	1.813	1.031	5.8
4B38SD	E1	3.4	3.8	4.15	SD	0.500" - 1.938"	2.469	1.813	1.031	6.2
4B40SD	E1	3.6	4.0	4.35	SD	0.500" - 1.938"	2.094	1.813	0.656	6.6
4B42SD	E1	3.8	4.2	4.55	SD	0.500" - 1.938"	2.094	1.813	0.656	6.9
4B44SD	E1	4.0	4.4	4.75	SD	0.500" - 1.938"	2.094	1.813	0.656	7.2
4B46SD	A1	4.2	4.6	4.95	SD	0.500" - 1.938"	0.656	1.813	0.781	7.6
4B48SD	A1	4.4	4.8	5.15	SD	0.500" - 1.938"	0.656	1.813	0.781	8.0
4B50SD	A1	4.6	5.0	5.35	SD	0.500" - 1.938"	0.656	1.813	0.781	8.4
4B52SD	A1	4.8	5.2	5.55	SD	0.500" - 1.938"	0.656	1.813	0.781	8.8
4B54SD	A1	5.0	5.4	5.75	SD	0.500" - 1.938"	0.656	1.813	0.781	8.2
4B56SD	A1	5.2	5.6	5.95	SD	0.500" - 1.938"	0.656	1.813	0.781	9.6
4B58SD	A1	5.4	5.8	6.15	SD	0.500" - 1.938"	0.656	1.813	0.781	10.0
4B60SD	A1	5.6	6.0	6.35	SD	0.500" - 1.938"	0.656	1.813	0.781	10.4
4B62SD	A1	5.8	6.2	6.55	SD	0.500" - 1.938"	0.656	1.813	0.781	10.8
4B64SD	A1	6.0	6.4	6.75	SD	0.500" - 1.938"	0.656	1.813	0.781	12.0
4B66SD	A1	6.2	6.6	6.95	SD	0.500" - 1.938"	0.656	1.813	0.781	12.4
4B68SD	A3	6.4	6.8	7.15	SD	0.500" - 1.938"	0.219	1.938	1.094	13.0
4B70SK	A1	6.6	7.0	7.35	SK	0.500" - 2.500"	0.219	1.938	1.094	13.5
4B74SK	A3	7.0	7.4	7.75	SK	0.500" - 2.500"	0.219	1.938	1.094	14.0
4B80SK	A3	7.6	8.0	8.35	SK	0.500" - 2.500"	0.219	1.938	1.094	15.5
4B86SK	A2	8.2	8.6	8.95	SK	0.500" - 2.500"	0.219	1.938	1.094	17.0
4B94SK	A3	9.0	9.4	9.75	SK	0.500" - 2.625"	0.219	1.938	1.094	19.0
4B110SK	A3	10.6	11.0	11.35	SK	0.500" - 2.625"	0.219	1.938	1.094	22.0
4B124SK	A3	12.0	12.4	12.75	SK	0.500" - 2.625"	0.219	1.938	1.094	29.0
4B136SK	A3	13.2	13.6	13.95	SK	0.500" - 2.625"	0.219	1.938	1.094	34.0
4B154SF	A3	15.0	15.4	15.75	SF	0.500" - 2.938"	0.156	2.063	1.031	39.0
4B160SF	A3	15.6	16.0	16.35	SF	0.500" - 2.938"	0.156	2.063	1.031	42.0
4B184SF	A3	18.0	18.4	18.75	SF	0.500" - 2.938"	0.156	2.063	1.031	47.0
4B200SF	A3	19.6	20.0	20.35	SF	0.500" - 2.938"	0.156	2.063	1.031	51.0
4B250E	D3	24.6	25.0	25.35	E	0.875" - 3.500"	0.156	2.75	0.656	73.0
4B300E	D3	29.6	30.0	30.35	E	0.875" - 3.500"	0.156	2.75	0.656	86.0
4B380E	D3	37.6	38.0	38.35	E	0.875" - 3.500"	0.156	2.75	0.656	109.0

TYPE A

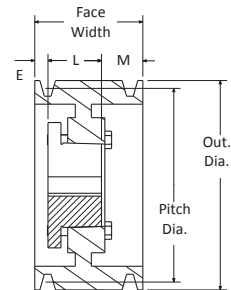

TYPE D

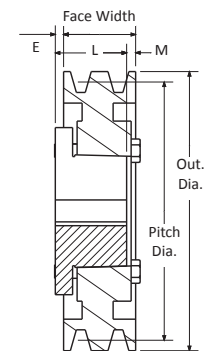

TYPE E

