

5V V-BELT SHEAVES

For 5V V-Belts

5 Grooves


3.750" Face Width

Cast Iron


QD® Style




TYPE A

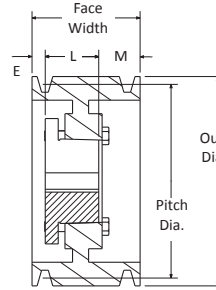


TYPE B

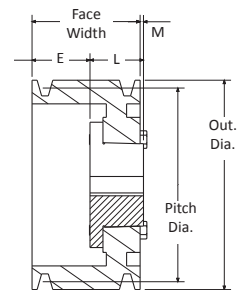


TYPE C

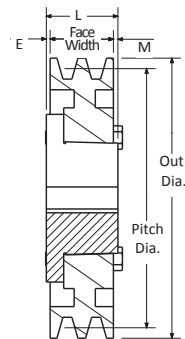

TYPE D

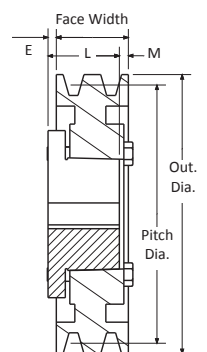

TYPE E

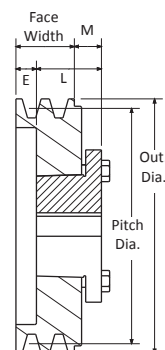

Part Number	Bushing	Bore Range	Type	Pitch Dia. "5V" Belts (in)	Out. Dia. (in)	E	L	M	Wt. Ea. (Lbs.)
55V440SD	SD	0.500" - 2.000"	E1	4.30	4.40	2.594	1.813	0.656	8.9
55V465SD	SD	0.500" - 2.000"	E1	4.55	4.55	2.594	1.813	0.656	9.2
55V490SD	SD	0.500" - 2.000"	A1	4.80	4.90	0.656	1.813	1.281	10.1
55V520SD	SD	0.500" - 2.000"	A1	5.10	5.20	0.656	1.813	1.281	10.8
55V550SD	SD	0.500" - 2.000"	A1	5.40	5.50	0.656	1.813	1.281	12.0
55V590SK	SK	0.500" - 2.625"	A1	5.80	5.90	0.531	1.938	1.281	13.2
55V630SK	SK	0.500" - 2.625"	A1	6.20	6.30	0.531	1.938	1.281	15.9
55V670SF	SF	0.500" - 2.938"	A1	6.60	6.60	0.531	2.063	1.156	18.6
55V710SF	SF	0.500" - 2.938"	A1	7.00	7.10	0.531	2.063	1.156	21.7
55V750SF	SF	0.500" - 2.938"	A1	7.40	7.50	0.531	2.063	1.156	22.8
55V800E	E	0.875" - 3.500"	A1	7.90	8.00	0.594	2.750	0.406	23.7
55V850E	E	0.875" - 3.500"	A1	8.40	8.50	0.594	2.750	0.406	24.8
55V900E	E	0.875" - 3.500"	A1	8.90	9.00	0.594	2.750	0.406	26.3
55V925E	E	0.875" - 3.500"	A1	9.15	9.25	0.594	2.750	0.406	28.2
55V975E	E	0.875" - 3.500"	A1	9.65	9.75	0.594	2.750	0.406	32.0
55V1030E	E	0.875" - 3.500"	A2	10.20	10.30	0.594	2.750	0.406	33.0
55V1090E	E	0.875" - 3.500"	A2	10.80	10.80	0.594	2.750	0.406	35.0
55V1130E	E	0.875" - 3.500"	A3	11.20	11.30	0.594	2.750	0.406	36.5
55V1180E	E	0.875" - 3.500"	A3	11.70	11.80	0.594	2.750	0.406	38.0
55V1250E	E	0.875" - 3.500"	A3	12.40	12.50	0.594	2.750	0.406	40.8
55V1320E	E	0.875" - 3.500"	A3	13.10	13.20	0.594	2.750	0.406	42.3
55V1400E	E	0.875" - 3.500"	A3	13.90	14.00	0.594	2.750	0.406	44.6
55V1500E	E	0.875" - 3.500"	A3	14.90	15.00	0.594	2.750	0.406	48.2
55V1600E	E	0.875" - 3.500"	A3	15.90	16.00	0.594	2.750	0.406	51.2
55V1870F	F	1.000" - 4.000"	D3	18.60	18.70	0.094	3.750	0.094	70.2
55V2120F	F	1.000" - 4.000"	D3	21.10	21.20	0.031	3.750	0.031	89.0
55V2360F	F	1.000" - 4.000"	D3	23.50	23.60	0.031	3.750	0.031	105.0
55V2800F	F	1.000" - 4.000"	D3	27.90	28.00	0.031	3.750	0.031	123.0
55V3150J	J	1.500" - 4.500"	C3	31.40	31.50	0.438	4.625	0.438	151.0
55V3750J	J	1.500" - 4.500"	C3	37.40	37.50	0.438	4.625	0.438	190.0
55V5000J	J	1.500" - 4.500"	C3	49.90	50.00	0.438	4.625	0.438	278.0