


# 2 MM POWERHOUSE™ TIMING PULLEY BAR STOCK

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)

## 2 mm Pitch Aluminum

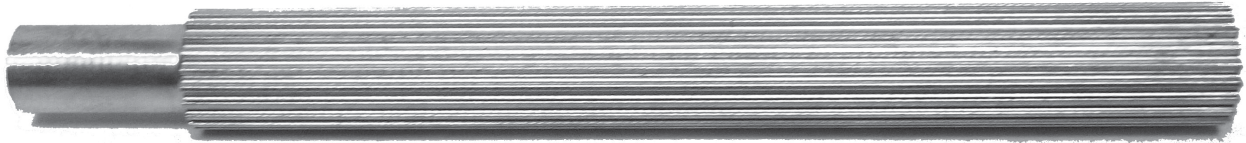

Timing Pulley Stock

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
35-2P-PS6A	35	22.3 mm	21.8 mm	0.877"	0.857"	0.500"	1.000"	6.000"	7.000"
36-2P-PS6A	36	22.9 mm	22.4 mm	0.902"	0.882"	0.500"	1.000"	6.000"	7.000"
37-2P-PS6A	37	23.5 mm	23.0 mm	0.927"	0.907"	0.500"	1.000"	6.000"	7.000"
38-2P-PS6A	38	24.2 mm	23.7 mm	0.952"	0.932"	0.500"	1.000"	6.000"	7.000"
39-2P-PS6A	39	24.8 mm	24.3 mm	0.977"	0.957"	0.500"	1.000"	6.000"	7.000"
40-2P-PS6A	40	25.5 mm	25.0 mm	1.003"	0.983"	0.500"	1.000"	6.000"	7.000"
42-2P-PS7A	42	26.7 mm	26.2 mm	1.053"	1.033"	0.500"	1.000"	7.000"	8.000"
44-2P-PS7A	44	28.0 mm	27.5 mm	1.103"	1.083"	0.500"	1.000"	7.000"	8.000"
45-2P-PS7A	45	28.7 mm	28.1 mm	1.128"	1.108"	0.500"	1.000"	7.000"	8.000"
48-2P-PS7A	48	30.6 mm	30.0 mm	1.203"	1.183"	0.500"	1.000"	7.000"	8.000"
50-2P-PS7A	50	31.8 mm	31.3 mm	1.253"	1.233"	0.500"	1.000"	7.000"	8.000"
52-2P-PS7A	52	33.1 mm	32.6 mm	1.303"	1.283"	0.500"	1.000"	7.000"	8.000"
54-2P-PS7A	54	34.4 mm	33.9 mm	1.353"	1.333"	0.500"	1.000"	7.000"	8.000"
55-2P-PS7A	55	35.0 mm	34.5 mm	1.379"	1.359"	0.500"	1.000"	7.000"	8.000"
56-2P-PS7A	56	35.7 mm	35.2 mm	1.404"	1.384"	0.500"	1.000"	7.000"	8.000"
60-2P-PS8A	60	38.2 mm	37.7 mm	1.504"	1.484"	0.500"	1.000"	8.000"	9.000"
64-2P-PS8A	64	40.7 mm	40.2 mm	1.604"	1.584"	0.500"	1.000"	8.000"	9.000"
65-2P-PS8A	65	41.4 mm	40.9 mm	1.629"	1.609"	0.500"	1.000"	8.000"	9.000"
66-2P-PS8A	66	42.0 mm	41.5 mm	1.654"	1.634"	0.500"	1.000"	8.000"	9.000"
70-2P-PS8A	70	44.6 mm	44.0 mm	1.754"	1.734"	0.500"	1.000"	8.000"	9.000"
72-2P-PS8A	72	45.8 mm	45.3 mm	1.805"	1.785"	0.500"	1.000"	8.000"	9.000"
80-2P-PS8A	80	50.9 mm	50.4 mm	2.005"	1.985"	0.750"	1.000"	8.000"	9.000"
82-2P-PS8A	82	52.2 mm	51.7 mm	2.055"	2.035"	0.750"	1.000"	8.000"	9.000"