

A-B COMBINATION V-BELT SHEAVES

For use with "A" or "B" Section Belts

5 Grooves

4.000" Face Width


Cast Iron

QD® Style



Part Number	Type	Pitch Dia. "A" belts (in)	Pitch Dia. "B" belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
5B34SD	E1	3.4	3.0	3.75	SD	0.500" - 2.000"	3.219	1.813	1.031	6.1
5B36SD	E1	3.6	3.2	3.95	SD	0.500" - 2.000"	3.219	1.813	1.031	6.6
5B38SD	E1	3.8	3.4	4.15	SD	0.500" - 2.000"	3.219	1.813	1.031	7.1
5B40SD	E1	4.0	3.6	4.35	SD	0.500" - 2.000"	2.844	1.813	0.656	7.4
5B42SD	E1	4.2	3.8	4.55	SD	0.500" - 2.000"	2.844	1.813	0.656	8.0
5B44SD	E1	4.4	4.0	4.75	SD	0.500" - 2.000"	2.844	1.813	0.656	8.5
5B46SD	A1	4.6	4.2	4.95	SD	0.500" - 2.000"	0.656	1.813	1.513	9.0
5B48SD	A1	4.8	4.4	5.15	SD	0.500" - 2.000"	0.656	1.813	1.513	9.4
5B50SD	A1	5.0	4.6	5.35	SD	0.500" - 2.000"	0.656	1.813	1.513	10.0
5B52SD	A1	5.2	4.8	5.55	SD	0.500" - 2.000"	0.656	1.813	1.513	10.4
5B54SK	A1	5.4	5.0	5.75	SK	0.500" - 2.625"	0.513	1.813	1.469	10.8
5B56SK	A1	5.6	5.2	5.95	SK	0.500" - 2.625"	0.513	1.813	1.469	11.3
5B58SK	A1	5.8	5.4	6.15	SK	0.500" - 2.625"	0.513	1.813	1.469	12.0
5B60SK	A1	6.0	5.6	6.35	SK	0.500" - 2.625"	0.513	1.813	1.469	14.0
5B62SK	A1	6.2	5.8	6.55	SK	0.500" - 2.625"	0.513	1.813	1.469	15.0
5B64SK	A1	6.4	6.0	6.75	SK	0.500" - 2.625"	0.513	1.813	1.469	16.0
5B66SK	A1	6.6	6.2	6.95	SK	0.500" - 2.625"	0.513	1.813	1.469	17.0
5B68SK	A1	6.8	6.4	7.15	SK	0.500" - 2.625"	0.513	1.813	1.469	18.0
5B70SF	A1	7.0	6.6	7.35	SF	0.500" - 2.938"	0.513	1.813	1.469	19.0
5B74SF	A2	7.4	7.0	7.75	SF	0.500" - 2.938"	0.513	1.813	1.469	20.0
5B80SF	A2	7.6	8.0	8.35	SF	0.500" - 2.938"	0.469	2.063	1.469	21.0
5B86SF	A2	8.2	8.6	8.95	SF	0.500" - 2.938"	0.469	2.063	1.469	22.0
5B94SF	A3	9.0	9.4	9.75	SF	0.500" - 2.938"	0.469	2.063	1.469	24.0
5B110SF	A3	10.6	11.0	11.35	SF	0.500" - 2.938"	0.469	2.063	1.469	29.0
5B124SF	A3	12.0	12.4	12.75	SF	0.500" - 2.938"	0.469	2.063	1.469	34.0
5B136SF	A3	13.2	13.6	13.95	SF	0.500" - 2.938"	0.469	2.063	1.469	38.0
5B154SF	A3	15.0	15.4	15.75	SF	0.500" - 2.938"	0.469	2.063	1.469	46.0
5B160SF	A3	15.6	16.0	16.35	SF	0.500" - 2.938"	0.469	2.063	1.469	49.0
5B184SF	A3	18.0	18.4	18.75	SF	0.500" - 2.938"	0.469	2.063	1.469	55.0
5B200E	A3	19.6	20.0	20.35	E	0.875" - 3.500"	0.094	2.75	1.156	65.0
5B250E	A3	24.6	25.0	25.35	E	0.875" - 3.500"	0.094	2.75	1.156	86.0
5B300E	A3	29.6	30.0	30.35	E	0.875" - 3.500"	0.094	2.75	1.156	102.0
5B380E	A3	37.6	38.0	38.35	E	0.875" - 3.500"	0.094	2.75	1.156	132.0

TYPE A

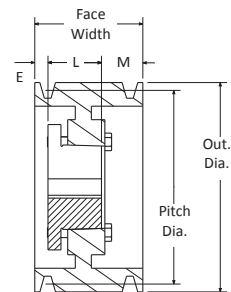

TYPE E

