

5 MM POWERHOUSE™ BELTS

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)


Standard Widths:

9 mm, 15 mm, 25 mm

Neoprene Construction

Fiberglass Reinforcements

(Note: Custom belt widths are available upon request.)

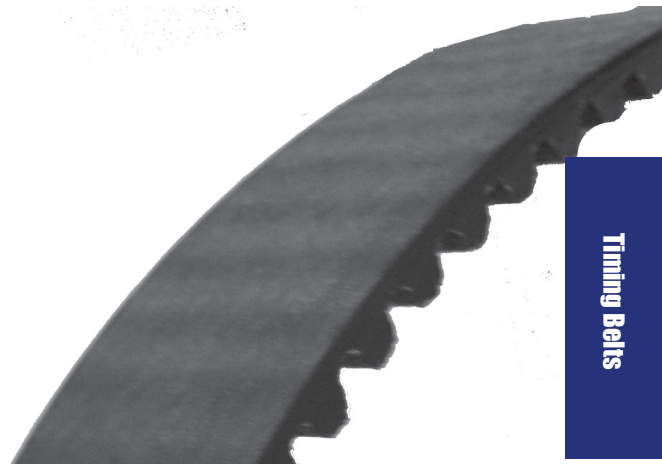

Timing Belts




Part Number	No. of Teeth	Pitch Length (mm)
200-5P	40	200.0
225-5P	45	225.0
250-5P	50	250.0
265-5P	53	265.0
275-5P	55	275.0
285-5P	57	285.0
300-5P	60	300.0
325-5P	65	325.0
330-5P	66	330.0
340-5P	68	340.0
350-5P	70	350.0
355-5P	71	355.0
360-5P	72	360.0
375-5P	75	375.0
400-5P	80	400.0
405-5P	81	405.0
410-5P	82	410.0


Part Number	No. of Teeth	Pitch Length (mm)
425-5P	85	425.0
450-5P	90	450.0
460-5P	92	460.0
475-5P	95	475.0
500-5P	100	500.0
525-5P	105	525.0
535-5P	107	535.0
540-5P	108	540.0
550-5P	110	550.0
565-5P	113	565.0
575-5P	115	575.0
580-5P	116	580.0
600-5P	120	600.0
625-5P	125	625.0
650-5P	130	650.0
700-5P	140	700.0
750-5P	150	750.0

Part Number	No. of Teeth	Pitch Length (mm)
800-5P	160	800.0
815-5P	163	815.0
850-5P	170	850.0
860-5P	172	860.0
900-5P	180	900.0
950-5P	190	950.0
1000-5P	200	1000.0
1050-5P	210	1050.0
1150-5P	230	1150.0
1300-5P	260	1300.0
1450-5P	290	1450.0
1600-5P	320	1600.0
1720-5P	344	1720.0
1755-5P	351	1755.0
2100-5P	420	2100.0
2440-5P	488	2440.0

Neoprene 5 mm POWERHOUSE™ timing belt part numbers can be determined as follows:
Pitch Length Code + -5P- + Width Code

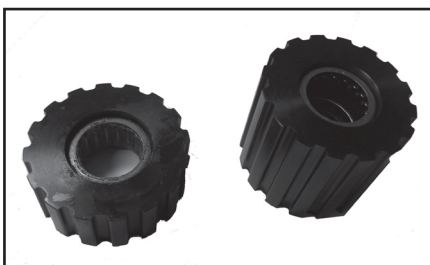

For idler pulleys, see page 366.

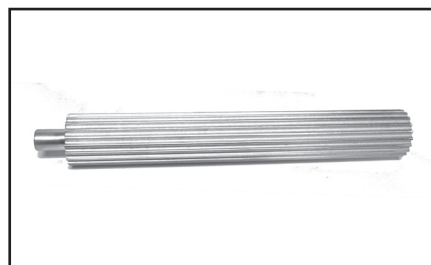

For 5 mm POWERHOUSE™ pulley stock and flanges, see page 317.



For 5 mm POWERHOUSE™ pitch timing pulleys, see page 135.