

# 5V V-BELT SHEAVES

For 5V V-Belts

6 Grooves

4.438" Face Width


Cast Iron

QD® Style




Part Number	Bushing	Bore Range	Type	Pitch Dia. "5V" Belts (in)	Out. Dia. (in)	E	L	M	Wt. Ea. (Lbs.)
65V440SD	SD	0.500" - 2.000"	E1	4.30	4.40	3.781	1.813	0.656	10.1
65V465SD	SD	0.500" - 2.000"	E1	4.55	4.55	3.781	1.813	0.656	10.4
65V490SD	SD	0.500" - 2.000"	A1	4.80	4.90	0.656	1.813	1.281	11.2
65V520SD	SD	0.500" - 2.000"	A1	5.10	5.20	0.656	1.813	1.281	12.1
65V550SD	SD	0.500" - 2.000"	A1	5.40	5.50	0.656	1.813	1.281	13.3
65V590SK	SK	0.500" - 2.625"	A1	5.80	5.90	0.531	1.938	1.281	14.6
65V630SK	SK	0.500" - 2.625"	A1	6.20	6.30	0.531	1.938	1.281	17.4
65V670SF	SF	0.500" - 2.938"	A1	6.60	6.60	0.781	2.063	1.156	20.0
65V710SF	SF	0.500" - 2.938"	A1	7.00	7.10	0.781	2.063	1.156	21.9
65V750SF	SF	0.500" - 2.938"	A1	7.40	7.50	0.781	2.063	1.156	23.4
65V800E	E	0.875" - 3.500"	A1	7.90	8.00	0.844	2.750	0.406	24.2
65V850E	E	0.875" - 3.500"	A1	8.40	8.50	0.844	2.750	0.406	26.7
65V900E	E	0.875" - 3.500"	A1	8.90	9.00	0.844	2.750	0.406	28.5
65V925E	E	0.875" - 3.500"	A1	9.15	9.25	0.844	2.750	0.406	30.2
65V975E	E	0.875" - 3.500"	A1	9.65	9.75	0.844	2.750	0.406	33.8
65V1030E	E	0.875" - 3.500"	A2	10.20	10.30	0.844	2.750	0.406	36.6
65V1090E	E	0.875" - 3.500"	A2	10.80	10.80	0.844	2.750	0.406	38.1
65V1130E	E	0.875" - 3.500"	A3	11.20	11.30	0.844	2.750	0.406	39.8
65V1180E	E	0.875" - 3.500"	A2	11.70	11.80	0.844	2.750	0.406	41.2
65V1250F	F	1.000" - 4.000"	B3	12.40	12.50	0.719	2.750	0.406	58.2
65V1320F	F	1.000" - 4.000"	B3	13.10	13.20	0.719	2.750	0.406	64.0
65V1400F	F	1.000" - 4.000"	B3	13.90	14.00	0.719	2.750	0.406	66.0
65V1500F	F	1.000" - 4.000"	B3	14.90	15.00	0.719	2.750	0.406	68.0
65V1600F	F	1.000" - 4.000"	B3	15.90	16.00	0.719	2.750	0.406	77.5
65V1870F	F	1.000" - 4.000"	D3	18.60	18.70	0.031	3.750	0.094	85.5
65V2120F	F	1.000" - 4.000"	D3	21.10	21.20	0.031	3.750	0.031	96.0
65V2360J	J	1.500" - 4.500"	C3	23.50	23.60	0.125	3.750	0.031	113.0
65V2800J	J	1.500" - 4.500"	C3	27.90	28.00	0.125	3.750	0.031	148.0
65V3150J	J	1.500" - 4.500"	C3	31.40	31.50	0.125	4.625	0.438	183.0
65V3750J	J	1.500" - 4.500"	C3	37.40	37.50	0.125	4.625	0.438	218.0
65V5000M	M	2.000" - 5.500"	C3	49.90	50.00	1.094	4.625	0.438	310.0


TYPE A

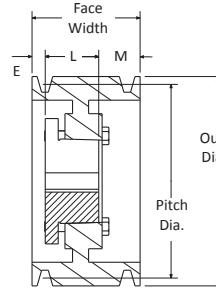


TYPE B

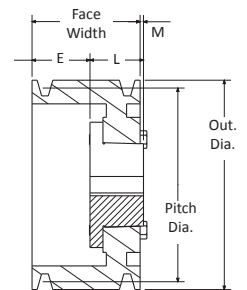

TYPE C

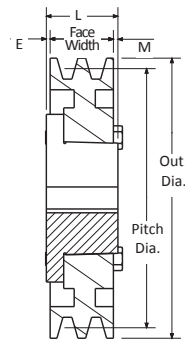

TYPE D

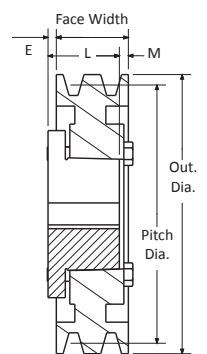

TYPE E

