

A-B COMBINATION V-BELT SHEAVES

For use with "A" or "B" Section Belts

6 Grooves

4.750" Face Width


Cast Iron

QD® Style



Part Number	Type	Pitch Dia. "A" belts (in)	Pitch Dia. "B" belts (in)	Out. Dia. (in)	Bushing	Bore Range	E	L	M	Wt. Ea. (Lbs.)
6B34SD	E1	3.4	3.0	3.75	SD	0.500" - 2.000"	3.969	1.813	1.031	6.7
6B36SD	E1	3.6	3.2	3.95	SD	0.500" - 2.000"	3.969	1.813	1.031	7.4
6B38SD	E1	3.8	3.4	4.15	SD	0.500" - 2.000"	3.969	1.813	1.031	8.0
6B40SD	E1	4.0	3.6	4.35	SD	0.500" - 2.000"	3.594	1.813	2.031	8.4
6B42SD	E1	4.2	3.8	4.55	SD	0.500" - 2.000"	3.594	1.813	2.031	9.0
6B44SD	E1	4.4	4.0	4.75	SD	0.500" - 2.000"	3.594	1.813	2.031	9.7
6B46SD	A1	4.6	4.2	4.95	SD	0.500" - 2.000"	0.656	1.813	2.281	10.1
6B48SD	A1	4.8	4.4	5.15	SD	0.500" - 2.000"	0.656	1.813	2.281	10.6
6B50SD	A1	5.0	4.6	5.35	SD	0.500" - 2.000"	0.656	1.813	2.281	11.0
6B52SD	A1	5.2	4.8	5.55	SD	0.500" - 2.000"	0.656	1.813	2.281	12.0
6B54SK	A1	5.4	5.0	5.75	SK	0.500" - 2.625"	0.844	2.063	1.844	13.0
6B56SK	A1	5.6	5.2	5.95	SK	0.500" - 2.625"	0.844	2.063	1.844	14.0
6B58SK	A1	5.8	5.4	6.15	SK	0.500" - 2.625"	0.844	2.063	1.844	14.6
6B60SK	A1	6.0	5.6	6.35	SK	0.500" - 2.625"	0.844	2.063	1.844	15.0
6B62SK	A1	6.2	5.8	6.55	SK	0.500" - 2.625"	0.844	2.063	1.844	16.0
6B64SK	A1	6.4	6.0	6.75	SK	0.500" - 2.625"	0.844	2.063	1.844	17.0
6B66SK	A1	6.6	6.2	6.95	SK	0.500" - 2.625"	0.844	2.063	1.844	18.0
6B68SK	A1	6.8	6.4	7.15	SK	0.500" - 2.625"	0.844	2.063	1.844	19.0
6B70SF	A1	7.0	6.6	7.35	SF	0.500" - 2.938"	0.844	2.063	1.844	20.0
6B74SF	A2	7.4	7.0	7.75	SF	0.500" - 2.938"	0.844	2.063	1.844	22.0
6B80SF	A2	7.6	8.0	8.35	SF	0.500" - 2.938"	0.844	2.063	1.844	24.0
6B86SF	A2	8.2	8.6	8.95	SF	0.500" - 2.938"	0.844	2.063	1.844	26.0
6B94SF	A3	9.0	9.4	9.75	SF	0.500" - 2.938"	0.844	2.063	1.844	27.0
6B110SF	A3	10.6	11.0	11.35	SF	0.500" - 2.938"	0.844	2.063	1.844	32.0
6B124SF	A3	12.0	12.4	12.75	SF	0.500" - 2.938"	0.844	2.063	1.844	39.0
6B136SF	A3	13.2	13.6	13.95	SF	0.500" - 2.938"	0.844	2.063	1.844	44.0
6B154SF	A3	15.0	15.4	15.75	SF	0.500" - 2.938"	0.844	2.063	1.844	50.0
6B160SF	A3	15.6	16.0	16.35	SF	0.500" - 2.938"	0.844	2.063	1.844	54.0
6B184SF	A3	18.0	18.4	18.75	SF	0.500" - 2.938"	0.844	2.063	1.844	62.0
6B200E	A3	19.6	20.0	20.35	E	0.875" - 3.500"	0.219	2.75	1.781	74.0
6B250E	A3	24.6	25.0	25.35	E	0.875" - 3.500"	0.219	2.75	1.781	96.0
6B300E	A3	29.6	30.0	30.35	E	0.875" - 3.500"	0.219	2.75	1.781	119.0
6B380E	A3	37.6	38.0	38.35	E	0.875" - 3.500"	0.219	2.75	1.781	134.0

TYPE A

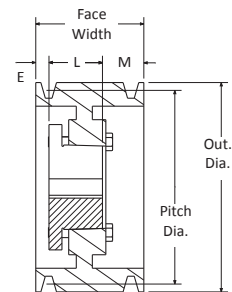

TYPE E

