



BRELLA

VANITIES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

2-4 light vanity luminaires featuring handcrafted glass.

LAMPING

Standard: 40W Low-pressure G9 Halogen, 120V, lamp included. Suitable for use in an open fixture. Dimmable with standard incandescent dimmer (not included).

LED: 5W Replaceable source, 120V, dimmable, 90+ CRI, 3000° K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.
6.0" Dia. x 4.0" H, spaced 7.875" apart on center.

CONSTRUCTION

Fixture utilizes metal arm assembly and stamped steel body, with plated finish. Decorative finials can be removed for downlighting applications. Decorative outlet box cover optional when not required.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

MOUNTING

Installs directly to a 4" octagonal outlet box, with 1.75" left or right offset. Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



BRELLA SHOWN IN WHITE (467907)

467983
MOCHA

4679SL
SOLARE

4679KR
CHALK

4679TN
TITAN

4679OK
OAK

4679CH
CHERRY



For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 7/22




ORDERING:

FIXTURE	GLASS OPTIONS	METAL FINISH	METAL FINISH	OPTIONS
2SW 2 Light Vanity	467907 White	(blank) 40W G9 Hal	BR Bronze	SQ Square Canopy
3SW 3 Light Vanity	467983 Mocha	LED 5W LED 120V, dimmable	CR Chrome	
4SW 4 Light Vanity	4679CH Cherry		SN Satin Nickel	
	4679KR Chalk			
	4679OK Oak			
	4679SL Solare			
	4679TN Titan			

Ex. 3SW-467983-SN

Brella 3-Light Vanity w/ Mocha Glass, Satin Nickel Finish

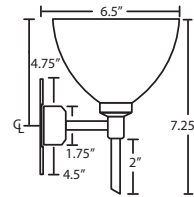

2SW: 14.625" L



3SW: 22.5" L



4SW: 30.375" L



Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

Project Information: